


Easy-mount Cam Follower Model CF-SFU

Optional specifications		Symbol
Roller guide	With cage	No Symbol
Material	Carbon steel	No Symbol
Seal	With seal	No Symbol
Outer ring shape	Cylindrical outer ring	No Symbol
	Spherical outer ring	R

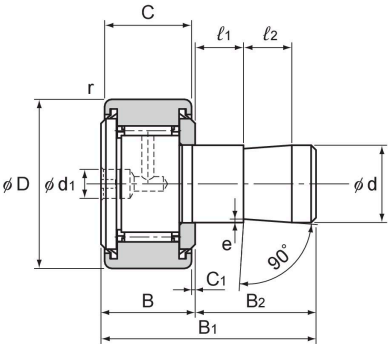

Stud diameter		Main dimensions											
		Outer diameter	Outer ring width		Overall length								
d	Model No.	D	C	B	B ₁	B ₂	C ₁	ℓ ₁	ℓ ₂	d ₁	r _{min}	e	
6	CF-SFU-6	16	11	12	32	20	0.6	5	10	4	0.3	0.3	
8	CF-SFU-8	19	11	12	32	20	0.6	5	10	4	0.3	0.5	
10	CF-SFU-10	22	12	13	33	20	0.6	5	10	4	0.3	0.5	
10	CF-SFU-10-1	26	12	13	33	20	0.6	5	10	4	0.3	0.5	
12	CF-SFU-12	30	14	15	35	20	0.6	5	10	6	0.6	1	
12	CF-SFU-12-1	32	14	15	35	20	0.6	5	10	6	0.6	1	
16	CF-SFU-16	35	18	19.5	44.5	25	0.8	10	10	6	0.6	1	
18	CF-SFU-18	40	20	21.5	46.5	25	0.8	10	10	6	1	1	
20	CF-SFU-20	52	24	25.5	50.5	25	0.8	10	10	8	1	1	
20	CF-SFU-20-1	47	24	25.5	50.5	25	0.8	10	10	8	1	1	

Note) For information on accuracy standards, please refer to **A19-14**.

Model number coding

CF-SFU-6 R -N

Model No.

No Symbol : Cylindrical outer ring
R : Spherical outer ring

No Symbol : No grease nipple
N : Dedicated grease nipple included (See **A19-39**)

Note) Model CF-SFU is fitted with UU seals even where no UU symbol is used.