

Prices displayed include 8% tax.

TRUSCO **Stock 38,650 Items**

## Chamfer Measurement Gauge

Calibration OK Approx. 2 Weeks RoHS

Com.eco Chemical Content Inspection Com. Drawing

- Features**
- Surface chamfer measurement of the workpiece in the lathe/unit plate/turret disk operation is possible.
  - Chamfering each side of the cube, and hole chamfering can be performed with milling machine and drilling machine.
  - It is with a ball chain convenient to carry.
- Use**
- To measure the size of various chamfer.
- Specs**
- Minimum reading value: 0.5mm
  - Instrumental difference: ±0.25mm
- Materials**
- Stainless Steel (SUS420J2)
- Origin**
- Japan



TG-15C

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Measurement Range (C)	SPQ (piece)	Weight (g)
229-5946	TG-15C	¥1,898	¥2,050	0 to 15	10	20

Contact us: 0120-509-849 <http://www.orange-book.com/>


TRUSCO **Stock 38,650 Items**

## C Surface Measurement Gauge

Calibration OK Approx. 30 days RoHS

Com.eco Chemical Content Inspection Com. Drawing

- Features**
- C plane measurement can be easily, quickly and accurately performed, improving work efficiency.
  - The thickness is 0.6mm.
- Use**
- For inspection of C face (45° chamfer).
- Specs**
- Precision: ±0.03mm
- Materials**
- Stainless Steel (SUS430)
- Origin**
- Japan

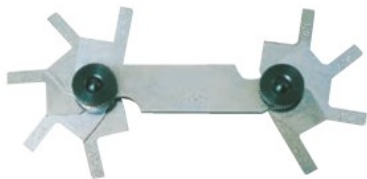

C-5

Order Unit: 1 Piece

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Measurement Range (mm)	Set Details (mm)	Number of Sheets (sheets)	SPQ (piece)	Weight (g)
229-6438	C-215	¥8,146	¥8,800	0.2 to 1.5 (per 0.1)	0.2 to 1.5 (per 0.1)	14	10	40
229-6446	C-163	¥8,146	¥8,800	1.6 to 3.0 (per 0.1)	1.6 to 3.0 (per 0.1)	15	10	43
229-6454	C-5	¥7,776	¥8,400	0.5 to 5.0 (per 0.5)	0.5 to 5.0 (per 0.5)	10	10	36
229-6462	C-10	¥8,887	¥9,600	5.5 to 10.0 (per 0.5)	5.5 to 10.0 (per 0.5)	10	10	100

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

## Pitch Gauge

Calibration OK Approx. 30 days RoHS

Com.eco Chemical Content Inspection Com. Drawing

- Features**
- The pitch of general screws can be measured easily and accurately.
- Use**
- For screw pitch.
- Materials**
- Cold rolled steel
- Origin**
- Japan



137 (for Inch)

**For inch** Specs • Precision: 60 to 40 threads (±0.03mm)/39 to 10 threads (±0.05mm)/9 to 4 threads (±0.07mm)

Order Unit: 1 Piece

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Dimension (mm)	Set Details (mm)	Number of Sheets (sheets)	SPQ (piece)	Weight (g)
229-5776	137	¥4,443	¥4,800	70 x 15	4, 41/2, 5 to 14 (per 1.0), 16, 18, 19, 20, 22, 24, 25, 26, 28, 30, 32, 40, 48, 60	26	10	57

**For millimeters** Specs • Precision: 0.25 to 1.3 (±0.03mm)/1.4 to 7.0 (±0.05mm)/7.5 to 11.5 (±0.07mm)

Order Unit: 1 Piece

(Price revision date: Jan, 2016)

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Dimension (mm)	Set Details (mm)	Number of Sheets (sheets)	SPQ (piece)	Weight (g)
229-5784	156	¥4,443	¥4,800	70 x 15	0.25 to 0.9 (per 0.05), 1.0 to 1.2 (per 0.1), 1.25, 1.3 to 1.7 (per 0.1), 1.75, 1.8, 1.9, 2.0, 2.5	28	10	60
229-5792	158	¥4,999	¥5,400	70 x 15	0.5 to 2.0 (per 0.25), 2.5 to 7.0 (per 0.5)	17	10	45
229-5806	159	¥4,999	¥5,400	87 x 20	1.0 to 11.5 (per 0.5)	22	10	80
229-5814	JIS	¥4,999	¥5,400	70 x 15	0.25 to 0.4 (per 0.05), 0.5, 0.75, 0.9, 1.0 to 2.0 (per 0.25), 2.5 to 6.0 (per 0.5)	21	10	53

Contact us: 0120-509-849 <http://www.orange-book.com/>

Micrometers

Micrometer Stands

Hole Tests

Micrometer Heads

Calipers

Height Gauges

Depth Gauges

Dial Indicators

Thickness Gauges

Bore Gauges

Gauges

Squares, Levelers

Linear Scales

Squares

Scales

Protractors

Scribers

Surface Plates