

Prices displayed include 8% tax.

TRUSCO **Stock 38,650 Items**

Center Gauge

Calibration OK Approx. 30 days RoHS

Com eco Chemical Content Inspection Com Drawing

Features •The cuts on the side can also be used to inspect the perpendicularity of the machine and blade.
Use •Angle of lathe center, for angle inspection of cutting tool for thread cutting.
Origin •Japan



651 (cold rolled steel)



60-Y (carbon steel tools A class quenching)

Cold rolled steel Specs •Precision: ±10' Materials •Cold rolled steel
 Order Unit: 1 Piece (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Measurement Range (°)	Scale	SPQ (piece)	Weight (g)
229-6039	651	¥1,481	¥1,600	55	1/14, 1/20, 1/24, 1/32 (inch)	10	12
229-6047	652	¥1,481	¥1,600	60	1, 1/2 (mm)	10	12

Carbon steel tools A class quenching Features •A quenching item. Specs •Precision: ±3'
 Materials •Carbon Steel Tools (Price revision date: Jan, 2016)

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Measurement Range (°)	Scale	SPQ (piece)	Weight (g)
229-6055	55-Y	¥10,090	¥10,900	55	No Scale	1	46
229-6063	60-Y	¥10,090	¥10,900	60	No Scale	1	46

Contact us:0120-509-849 <http://www.orange-book.com/>

SK **Stock 1,103 Items**

Center Gauge

New



SG-60M

Features •Blade edge angle of tool bit for standard threading can be inspected.
Use •For angle inspection of tool bit blade shapes when threading in lathe, etc.
Materials •Carbon Steel for Mechanical Structures Origin •China

Order Unit: 1 Piece NIIGATASEIKI Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Possible measurement angle (°)	Scale	SPQ (piece)	Weight (g)
817-7546	SG-60M	¥1,620	¥1,500	60	0 to 25mm Per 0.5mm/Per 1mm	6	10

Contact us:0256-31-5660 <http://www.sokuteikougu.com/>

TRUSCO **Stock 38,650 Items**

Angle gauge

Calibration OK Approx. 30 days RoHS

Com eco Chemical Content Inspection Com Drawing

Features •This gauge is used for angle inspection.
Use •Inspection of inner angle for angle test of acme screw 14.5°.
Specs •Precision: ±10'
Materials •Cold rolled steel
Origin •Japan



466

Order Unit: 1 Piece (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Measurement Range (°)	Number of Sheets (sheets)	SPQ (piece)	Weight (g)
229-6276	466	¥11,942	¥12,900	1, 2, 3, 4, 5, 7, 8, 9, 10, 12, 14, 14.5, 15, 20, 25, 30, 35, 45	18	10	155

Contact us:0120-509-849 <http://www.orange-book.com/>

SK **Stock 1,103 Items**

Angle Limit Gauge

Calibration OK Approx. 2 Weeks



WAL2542

Features •Limit gauge for measurement of coupling bevel angle/butt coupling bevel angle.
 •Gauge leaf 4 sheets set.
Use •For measurement of coupling bevel angle/butt coupling bevel angle.
Specs •Instrumental error: ±0.1mm (length), ±1° (angle)
Materials •Stainless Steel
Origin •Japan

Order Unit: 1 Piece NIIGATASEIKI Co.Ltd.


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Possible measurement angle (°)	Possible measurement throat depth (mm)	Possible measurement leg length (mm)	SPQ (piece)	Weight (g)
377-6794	WAL2542	¥11,880	¥11,000	25 to 42.5(2.5° pitch)	4, 5, 6, 7	5, 7, 8, 10	10	100
377-6808	WAL4562	¥11,880	¥11,000	45 to 62.5(2.5° pitch)	8, 9, 10, 11	11, 13, 14, 15	10	120

Contact us:0256-31-5660 <http://www.sokuteikougu.com/>

SK **Stock 1,103 Items**

Route Interval Limit Gauge

Calibration OK Approx. 2 Weeks

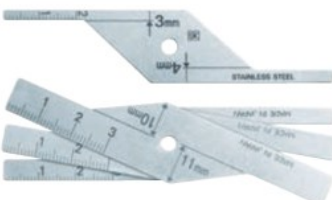

WRL310

Features •Limit gauge for measurement of route interval/butt coupling route interval.
 •Gauge leaf 4 sheets set.
Use •For measurement of route interval/butt coupling route interval.
Specs •Instrumental difference: ±0.1mm
Materials •Stainless Steel Origin •Japan

Order Unit: 1 Piece NIIGATASEIKI Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Possible measurement route interval (mm)	Possible measurement leg length (mm)	SPQ (piece)	Weight (g)
377-6824	WRL1118	¥11,880	¥11,000	11 to 18(1mm pitch)	2 to 9(1mm pitch)	10	90
377-6832	WRL310	¥11,880	¥11,000	3 to 10(1mm pitch)	10 to 17(1mm pitch)	10	60

Contact us:0256-31-5660 <http://www.sokuteikougu.com/>