

TRUSCO

TRUSCO

Stock  
38,650  
Items

## Flat Precision Split Level A Class

Repairing  
OKCalibration OK  
Approx. 2 Weeks

RoHS

.Com  
Drawing

- Features • Mainly for precision measurement of machine tools and flatness measurement of surface plates.
- Origin • Japan

Example



| A class                                                        |                      | Sensitivity |             |
|----------------------------------------------------------------|----------------------|-------------|-------------|
|                                                                |                      | 0.02        | 0.05        |
| Instruction precision                                          | Full Range Precision | ± 0.5 Scale | ± 0.3 Scale |
|                                                                | Adjacent precision   | 0.2 Scale   |             |
| Angle formed by the plane having the V groove and the V groove |                      | 0.5 Scale   |             |
| Bottom Flatness                                                |                      | 0.003mm     | 0.005mm     |



TFL-A1502

Order Unit: 1 Piece

(Price revision date: Jan, 2018) TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No.  | Price (per piece) | MSRP (per piece) | L x W x Thickness (mm) | Sensitivity (mm) | SPQ (piece) | Weight (kg) |
|------------|-----------|-------------------|------------------|------------------------|------------------|-------------|-------------|
| 232-6744   | TFL-A1502 | ¥126,360          | ¥136,500         | 150 x 45 x 55          | 0.02             | 1           | 1.6         |
| 232-6752   | TFL-A2002 | ¥134,599          | ¥145,400         | 200 x 50 x 55          | 0.02             | 1           | 2.0         |
| 263-0842   | TFL-A2502 | ¥156,927          | ¥169,520         | 250 x 50 x 55          | 0.02             | 1           | 2.5         |
| 263-0869   | TFL-A3002 | ¥175,423          | ¥189,500         | 300 x 50 x 55          | 0.02             | 1           | 3.0         |
| 263-0826   | TFL-A1505 | ¥125,434          | ¥135,500         | 150 x 45 x 55          | 0.05             | 1           | 1.6         |
| 263-0834   | TFL-A2005 | ¥133,673          | ¥144,400         | 200 x 50 x 55          | 0.05             | 1           | 2.0         |
| 263-0851   | TFL-A2505 | ¥156,002          | ¥168,520         | 250 x 50 x 55          | 0.05             | 1           | 2.5         |
| 263-0877   | TFL-A3005 | ¥174,497          | ¥188,500         | 300 x 50 x 55          | 0.05             | 1           | 3.0         |

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO

TRUSCO

Stock  
38,650  
Items

## Flat Precision Split Level


Repairing  
OKCalibration OK  
Approx. 2 Weeks

RoHS

.Com  
Drawing

- Features • Scale error of the main bubble tube is within 2 scales.
- Mainly suitable for leveling machine tools and the like.
- Specs • Precision: within 2 Scale divisions
- Origin • Japan

Example

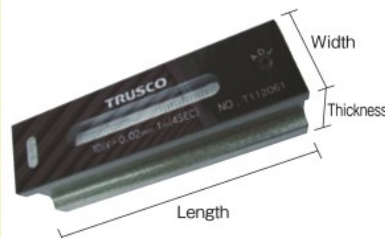

TFL-B1502

Order Unit: 1 Piece

(Price revision date: Jan, 2018) TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No.  | Price (per piece) | MSRP (per piece) | L x W x Thickness (mm) | Sensitivity (mm) | SPQ (piece) | Weight (kg) |
|------------|-----------|-------------------|------------------|------------------------|------------------|-------------|-------------|
| 232-6701   | TFL-B1502 | ¥47,379           | ¥51,180          | 150 x 48 x 45          | 0.02             | 1           | 1.6         |
| 232-6710   | TFL-B2002 | ¥55,728           | ¥60,200          | 200 x 48 x 45          | 0.02             | 1           | 2.0         |
| 263-0885   | TFL-B2502 | ¥63,134           | ¥68,200          | 250 x 48 x 45          | 0.02             | 1           | 2.5         |
| 263-0907   | TFL-B3002 | ¥71,280           | ¥77,000          | 300 x 48 x 45          | 0.02             | 1           | 3.0         |
| 232-6728   | TFL-B1505 | ¥45,443           | ¥49,090          | 150 x 48 x 45          | 0.05             | 1           | 1.6         |
| 232-6736   | TFL-B2005 | ¥54,793           | ¥59,190          | 200 x 48 x 45          | 0.05             | 1           | 2.0         |
| 263-0893   | TFL-B2505 | ¥62,208           | ¥67,200          | 250 x 48 x 45          | 0.05             | 1           | 2.5         |
| 263-0915   | TFL-B3005 | ¥71,280           | ¥77,000          | 300 x 48 x 45          | 0.05             | 1           | 3.0         |

Contact us: 0120-509-849 <http://www.orange-book.com/>

OSS

O.S.S.

Stock  
52  
Items

## Flat Precision Split Level

Repairing  
OKCalibration OK  
Approx. 2 Weeks

- Features • Suitable for leveling surface plate and machine tools, etc.
- The main body is made of high quality cast iron (FC250) and plane and sole of the bottom is precisely produced.
- With two M5 tapped holes on the rear side of the main body, can be installed to a measurement pitch flexible base or any workpieces.
- Inspection result document is attached as standard.
- Specs • Precision: within ±0.7 scale error of the main bubble tube
- Origin • Japan

Ohnishi Mfg.



201-150

Order Unit: 1 Piece

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | L x W x Thickness (mm) | Sensitivity (mm) | SPQ (piece) | Weight (kg) |
|------------|----------|-------------------|------------------|------------------------|------------------|-------------|-------------|
| 760-5277   | 201-100  | ¥46,440           | ¥43,000          | 100 x 44 x 45          | 0.02             | 1           | 1.0         |
| 760-5285   | 201-150  | ¥47,520           | ¥44,000          | 150 x 44 x 45          | 0.02             | 1           | 1.3         |
| 760-5293   | 201-200  | ¥56,160           | ¥52,000          | 200 x 44 x 45          | 0.02             | 1           | 1.8         |
| 760-5307   | 201-250  | ¥62,640           | ¥58,000          | 250 x 44 x 45          | 0.02             | 1           | 2.2         |
| 760-5315   | 201-300  | ¥69,120           | ¥64,000          | 300 x 44 x 45          | 0.02             | 1           | 2.4         |

Contact us: 06-6730-3031 <http://www.oss-ohnishi.com/>

RIKEN KEISOKUKI

RIKEN

Stock  
14  
Items

## Flat Precision Split Level

Repairing  
OKCalibration OK  
Approx. 2 Weeks

- Features • Used for assembly/leveling of machines.
- Precise grinded finish is applied to the working surface.
- Portable, convenient to carry.
- Specs • Precision: within 2 Scale divisions
- Materials • FC250
- Surface: Paint or coating
- Origin • Japan

Example



RIKEN KEISOKUKI MFG.CO.LTD



RFL-1002

Order Unit: 1 Piece

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | L x W x Thickness (mm) | Sensitivity (mm/m) | SPQ (piece) | Weight (kg) |
|------------|----------|-------------------|------------------|------------------------|--------------------|-------------|-------------|
| 487-5141   | RFL-1002 | ¥41,310           | ¥51,000          | 100 x 36 x 38          | 0.02               | 1           | 0.8         |
| 833-8778   | RFL-1005 | ¥40,500           | ¥50,000          | 100 x 36 x 38          | 0.05               | 1           | 0.8         |
| 833-8777   | RFL-1010 | ¥39,690           | ¥49,000          | 100 x 36 x 38          | 0.10               | 1           | 0.8         |

Contact us: 025-794-2401 <http://e-riken.com/>