

Prices displayed include 8% tax.

For Microscope Lights, see p. 1-1397 to 1398

Optical Precision Measuring Instruments

TRUSCO
 Stock 38,650 Items

Variable Magnification Stereoscopic Microscope


Repairing OK

Com Drawing



TXT-2040

- Features**
- Ideal for continuous inspection of parts with the same size and shape.
 - The base surface is enlarged, making it easy for an object to be mounted.
 - Anyone can operate easily, as lenses do not need to be switched.
 - Adjustable within the interpupillary distance range of 55 to 75mm.
 - With eye shade.
- Specs**
- Mirror Body Model: Binocular Magnification
 - Vertical Lighting: No
 - Transmitted Illumination: No
- Origin**
- China

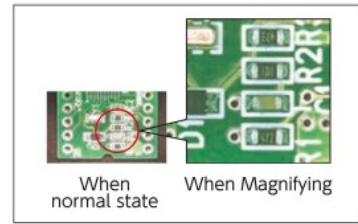

SPQ: 1 Piece

Order Unit: 1 Piece

(Price revision date: Jan, 2018) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Magnification (time)	Objective Lens (time)	Eye-piece Lens (time)	Number of Visual Field (mm)	Working Distance (mm)	Observable Height (mm)	W x D x H (mm)	Weight (kg)
329-2347	TXT-2040	¥49,005	¥60,500	20/40	2/4	10	19	105	160	285 x 295 x 340	3.7

Contact us:0120-509-849 <http://www.orange-book.com/>

Surface Roughness Testers

Shape Measuring Instruments

Stereo Microscopes

Microscopes

Illuminated Magnifiers

Lighting for Inspection

Loupe

Inspection Mirrors

Binoculars, Monocles

Drones

Wearable Cameras

Time Lapse Cameras

3D Printers

HOZAN
 Stock 452 Items

Variable Magnification Stereoscopic Microscope

Repairing OK RoHS



L-51

- Features**
- A stereoscopic microscope that can be used for a wide range of operations.
 - Operations become easy with long working distance and a wide visual field.
 - Anti-static feature enables its use in electronic components and equipment.
 - Cross section of a long object, etc. can be viewed by removing the round plate in the center and putting the object through the bottom.
- Specs**
- Mirror Body Model: Binocular Magnification
 - Vertical Lighting: No
 - Transmitted Illumination: No
- Origin**
- China



SPQ: 1 Piece

Order Unit: 1 Piece

(Price revision date: Jan, 2015) HOZAN TOOL INDUSTRIAL Co.Ltd.


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Magnification (time)	Objective Lens (time)	Eye-piece Lens (time)	Number of Visual Field (mm)	Working Distance (mm)	Observable Height (mm)	W x D x H (mm)	Weight (kg)
433-9983	L-51	¥55,383	¥54,700	10/20	1/2	WF10	10/20	84	84	200 x 255 x 450	3.8

Contact us:06-6567-3132 <http://www.hozan.co.jp/>

HOZAN
 Stock 452 Items


Variable Magnification Stereoscopic Microscope

Repairing OK RoHS

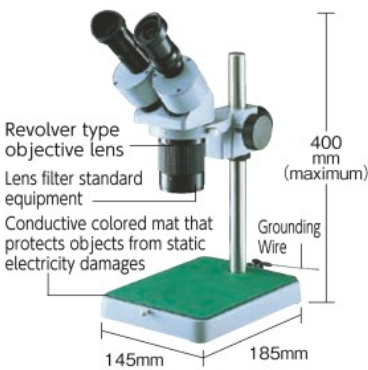

L-50

- Features**
- A standard stereoscopic microscope model which is highly adaptable in various types of work associated with electronic equipment.
 - Equipped with an anti-static conductive color mat and a lens filter that protects lens from soldering fumes.
 - Magnification of the objective lens can be switched by turning the revolver (rotating type) 90°.
- Specs**
- Mirror Body Model: Binocular Magnification
 - Vertical Lighting: No
 - Transmitted Illumination: No
- Origin**
- Japan

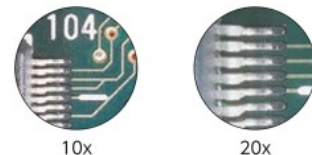

SPQ: 1 Piece

Order Unit: 1 Piece

(Price revision date: Jan, 2015) HOZAN TOOL INDUSTRIAL Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Magnification (time)	Objective Lens (time)	Eye-piece Lens (time)	Number of Visual Field (mm)	Working Distance (mm)	Observable Height (mm)	W x D x H (mm)	Weight (kg)
119-6375	L-50	¥83,025	¥82,000	10/20	1/2	WF10	9/18	80	80	145 x 185 x 400	2.4

Contact us:06-6567-3132 <http://www.hozan.co.jp/>

SHIMADZU
 Stock 2 Items

Variable Magnification Stereo Microscope (with lighting)

Repairing OK



VCT-VBL1E

- Features**
- LED is adopted for the vertical and transmitted illumination, enabling long life and low power consumption.
 - The objective lens is one touch rotation variable magnification type. Can be switched between 20x and 40x magnifications without changing the lens.
- Specs**
- Mirror Body Model: Binocular Magnification
 - Vertical Illumination: LED x 5
 - Transmitted Illumination: LED x 1
 - Power: AC100V (rechargeable/cordless)
- Origin**
- China

Item No.	Lens-barrel
VCT-VBL1E	Fixed Type
VCT-VBL2E	360° Rotation Type

SPQ: 1 Piece

Order Unit: 1 Piece

SHIMADZU RIKA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Magnification (time)	Objective Lens (time)	Eye-piece Lens (time)	Number of Visual Field (mm)	Working Distance (mm)	Observable Height (mm)	W x D x H (mm)	Weight (kg)
453-7041	VCT-VBL1E	¥32,184	¥29,800	20/40	2/4	10	20	45	68	115 x 187 x 345	2.5
453-7050	VCT-VBL2E	¥42,120	¥39,000	20/40	2/4	10	20	75	70	115 x 187 x 355	2.5

Contact us:03-5626-0210 <http://www.shimadzu-rika.co.jp/>