

Grip Pliers (for sheet metal processing/welding)

The number next to the logo mark indicates items in stock for each brand.

Clamps • Vices

Toggle Clamps

Hand Vices

Grip Pliers

C-Clamps

L Type Clamp

Clamps for Temporary Structures

Welding Clamps

Hand Clamps

Bar Clamps

Special Clamps

Vices


Parts for Vices

TRUSCO Stock **38,650** Items

G Type Grip Pliers (round type)



- Features**
- Optimum for welding positioning of pipe kind.
- Specs**
- Head Hardness: HRC40 to 45
- Materials**
- Special Steel
- Origin**
- China

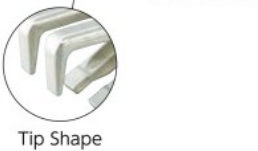

For Replacement Springs, see p. 4-1765

Opening (mm)			
Square Timber		Pipe	
Min	Max	Min	Max
8	70	φ8	φ70

Order Unit: 1 Piece (Price revision date: Jan, 2015) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Clamping Pressure (kN)	SPQ (piece)	Weight (g)
374-7255	TVPG-280R	¥3,055	¥3,300	280	2.5	1	1055



Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock **38,650** Items

C-type Grip Plier



- Features**
- Suitable for positioning work across angles during welding because the throat is deep.
- Specs**
- With nut
- Materials**
- Chromium Molybdenum Steel
- Origin**
- Taiwan

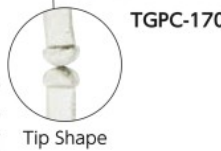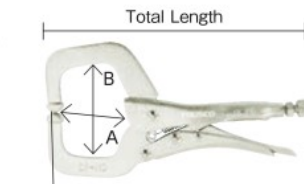

Item No.	Max Opening (mm)	Max Clamping Pressure (kN)
TGPC-170	40	3.9
TGPC-285	75	5.9
TGPC-450	120	1.0
TGPC-610	140	0.4


Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Jaw Depth A (mm)	Jaw Depth B (mm)	SPQ (piece)	Weight (g)
818-8067	TGPC-170	¥1,759	¥1,900	170	35	60	36	240
818-8069	TGPC-285	¥2,962	¥3,200	285	65	96	10	740
818-8071	TGPC-450	¥5,554	¥6,000	450	225	107	10	1140
818-8073	TGPC-610	¥6,665	¥7,200	610	390	113	10	1410

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock **38,650** Items

C Type Grip Pliers (with flexible fittings)

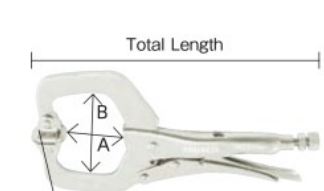

- Features**
- Securely clamp and hold different shape objects and angled works because of the specification that the tip part has flexible (swivel) metal fittings.
- Specs**
- With nut
- Materials**
- Chromium Molybdenum Steel
- Origin**
- Taiwan

Item No.	Max Opening (mm)	Max Clamping Pressure (kN)
TGPC-170S	40	3.9
TGPC-285S	70	5.9
TGPC-450S	120	1.0
TGPC-610S	140	0.4

Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Jaw Depth A (mm)	Jaw Depth B (mm)	SPQ (piece)	Weight (g)
818-8068	TGPC-170S	¥2,037	¥2,200	170	35	60	36	250
818-8070	TGPC-285S	¥2,962	¥3,200	285	65	106	10	750
818-8072	TGPC-450S	¥5,277	¥5,700	450	225	114	10	1150
818-8074	TGPC-610S	¥7,128	¥7,700	610	390	116	10	1410



Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock **38,650** Items

C-type Grip Plier



- Features**
- Optimum for welding positioning across angles. The thickness of the tooth part is 15mm.
- Specs**
- Head Hardness: HRC38 to 48
- Materials**
- Special Steel
- Origin**
- China

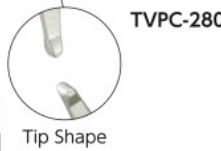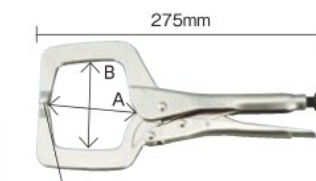

Max Opening (mm)	Max Clamping Pressure (kN)	
	Square Timber	Pipe
95	φ100	4.0

Order Unit: 1 Piece (Price revision date: Jan, 2015) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Jaw Depth A (mm)	Jaw Depth B (mm)	SPQ (piece)	Weight (g)
374-7263	TVPC-280	¥2,750	¥2,970	275	86	90	1	765


Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock **38,650** Items

C Type Grip Pliers (with flexible fittings)



- Features**
- Can clamp an angled target object with a large area because the tip has adjustable metal fitting (metal fitting width 27mm).
- Specs**
- Head Hardness: HRC38 to 48
- Materials**
- Special Steel
- Origin**
- China

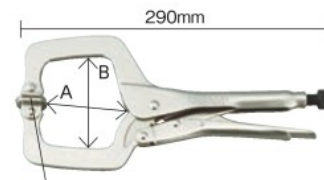

Max Opening (mm)	Max Clamping Pressure (kN)	
	Square Timber	Pipe
95	φ100	4.0

Order Unit: 1 Piece (Price revision date: Jan, 2015) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Jaw Depth A (mm)	Jaw Depth B (mm)	SPQ (piece)	Weight (g)
374-7271	TVPC-280S	¥2,657	¥2,870	290	70	88	1	805


Contact us: 0120-509-849 <http://www.orange-book.com/>

KNIPLEX Stock **942** Items

C-type Grip Plier



- Features**
- Durable against large load and can grip and hold various shape works.
 - With an adjusting screw and a release lever, which can be operated by one hand.
- Materials**
- High strength rolled steel (zinc plating)
 - Jaw part: Chrome vanadium steel
- Origin**
- Germany

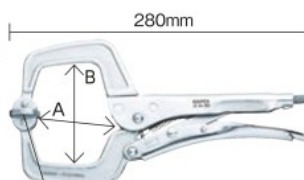

SPQ: 1 Piece

Order Unit: 1 Piece KNIPLEX-Werk C. Gustav Putsch KG

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	Jaw Depth A (mm)	Jaw Depth B (mm)	Weight (g)
836-8967	4244-280	¥7,020	¥7,000	280	90	65	95	740

URL <http://www.orange-book.com/>