

# L Type Clamps

The number next to the logo mark indicates items in stock for each brand.

Clamps · Vices

Toggle Clamps

Hand Vices

Grip Pliers

C-Clamps

L Type Clamp

Clamps for Temporary Structures

Welding Clamps

Hand Clamps

Bar Clamps

Special Clamps


Vices

Parts for Vices



Stock 38,650 Items

## Deep F Type Clamp

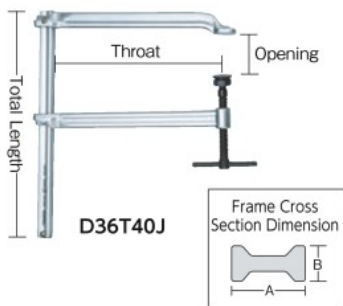

- Features ● Because of long size, it can be clamped deeply.  
 Materials ● Cold Rolled Steel Material  
 Accessories ● Flat Pad (T22-FP)  
 Origin ● Taiwan

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	Throat (mm)	Frame Dimension (mm)		SPQ (piece)	Weight (kg)
							A	B		
490-1029	D22T20J	¥ 8,702	¥ 9,400	321	200	200	22	10.5	4	1.65
490-1037	D25T25J	¥ 10,767	¥ 11,630	382	250	250	25	12.0	4	2.57
490-1045	D27T30J	¥ 12,599	¥ 13,610	434	300	300	27	13.0	4	3.39
490-1053	D30T36J	¥ 15,506	¥ 16,750	458	300	360	30	15.0	4	4.85
490-1061	D36T30J	¥ 19,625	¥ 21,200	465	300	300	36	18.0	2	5.90
490-1070	D36T40J	¥ 22,087	¥ 23,860	573	400	400	36	18.0	2	7.21
490-1088	D36T50J	¥ 24,541	¥ 26,510	573	400	500	36	18.0	2	8.55

TRUSCO NAKAYAMA CORPORATION

### Parts

Order Unit: 1 Piece

(Price revision date: Jan, 2017)

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Item Name	Applicable frame dimension A (mm)	SPQ (piece)	Weight (g)
490-1380	T22-FP	¥ 463	¥ 500	Flat Pad	19.5, 22.0	10	20
490-1401	T22-MP	¥ 509	¥ 550	Pad with Groove	19.5, 22.0	10	20
490-1428	T22-VP	¥ 814	¥ 880	V Pad	19.5, 22.0	10	20

### Joint

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Item Name	Applicable frame dimension A (mm)	SPQ (piece)	Weight (g)
490-1398	T22-J	¥ 509	¥ 550	Joint for Pad	19.5, 22.0	10	20

### Nut

Order Unit: 1 Piece


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Item Name	Applicable frame dimension A (mm)	SPQ (piece)	Weight (g)
490-1410	T22-N	¥ 463	¥ 500	Nut for Pad	19.5, 22.0	10	20

Contact us: 0120-509-849 <http://www.orange-book.com/>




Stock 38,650 Items

## Cantilever Type Clamp

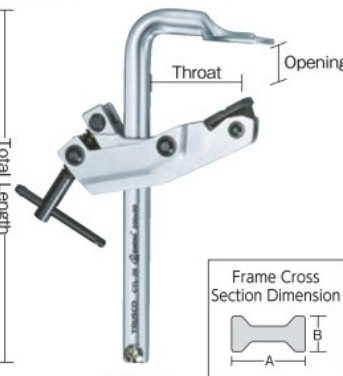

- Features ● Because the tightening handle is attached to the outside of the rail, it can be used in a narrow place.  
 ● By swapping the arm part and attaching the CTD of the separately sold attachment, you can work to spread out.  
 ● You can hold pipes, angles, etc. by installing CTV of the separately sold pad.  
 ● For steel and sheet metal.  
 Materials ● Cold Rolled Steel Material  
 Origin ● Taiwan

- Immobile work with steps ● Immobile work with inclination ● Immobile round pipe and square pipe

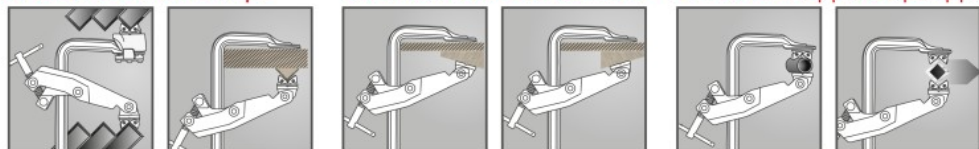

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	Throat (mm)	Frame Dimension (mm)		SPQ (piece)	Weight (kg)
							A	B		
490-1096	CTL-15	¥ 7,545	¥ 8,150	247	150	80	22	10.5	10	1.36
490-1100	CTL-20	¥ 7,721	¥ 8,340	297	200	80	22	10.5	10	1.44
490-1134	CTL-30	¥ 14,080	¥ 15,210	435	300	100	27	13.0	5	2.72
490-1118	CTL-50	¥ 8,997	¥ 9,720	597	500	80	22	10.5	10	1.93
490-1126	CTL-80	¥ 10,192	¥ 11,010	897	800	80	22	10.5	10	2.42
490-1142	CTL-60	¥ 15,607	¥ 16,860	735	600	100	27	13.0	5	3.46
490-1151	CTL-100	¥ 18,681	¥ 20,180	1135	1000	100	27	13.0	5	4.41

### Pad

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Compatible Model	SPQ (piece)	Weight (g)
490-1177	CTD-1	¥ 1,102	¥ 1,190	CTL-15, CTL-20, CTL-50, CTL-80	10	300
490-1185	CTD-2	¥ 1,194	¥ 1,290	CTL-30, CTL-60, CTL-100	10	310
490-1169	CTV	¥ 1,194	¥ 1,290	CTL-15, CTL-20, CTL-50, CTL-30, CTL-60, CTL-80, CTL-100	10	72

Contact us: 0120-509-849 <http://www.orange-book.com/>