


TRUSCO Stock 38,650 Items

Urethane Soft Hammer

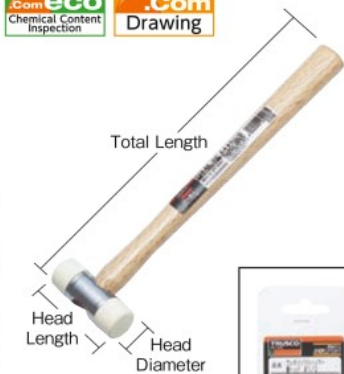

TUS-05



TUS-05H (replacement head)

- Features**
- Adopted the urethane resin head of JISA90 hardness.
 - With moderate hardness and softness, can be used pervasively.
- Materials**
- Head: Urethane resin
 - Handle: Oak
- Origin**
- Japan

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Designation	Head Diameter (mm)	Head Length (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
271-9951	TUS-05	¥1,324	¥1,430	1/2 Pound	26	72	285	6	240
271-9860	TUS-10	¥1,713	¥1,850	1 Pound	32	86	305	6	440
271-9878	TUS-15	¥2,258	¥2,440	1 1/2 Pound	38	100	360	6	715
271-9886	TUS-20	¥2,829	¥3,055	2 Pound	42	110	360	6	925

TRUSCO NAKAYAMA CORPORATION

Replacement Head


Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Head Diameter (mm)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
271-9894	TUS-05H	¥ 509	¥ 550	26	2	10	8
271-9908	TUS-10H	¥ 666	¥ 720	32	2	10	13
271-9916	TUS-15H	¥1,065	¥1,150	38	2	10	20
271-9924	TUS-20H	¥1,296	¥1,400	42	2	10	28

Contact us: 0120-509-849 <http://www.orange-book.com/>

BAHCO Stock 2,057 Items

A hammer suitable for works in high places

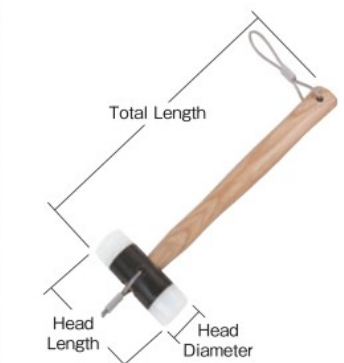

TAH3625W-35

- Features**
- A hammer with lanyard loops suitable for works in high places.
 - With a nylon striking face which is less likely to scratch the workpiece.
- Materials**
- Nylon
- Origin**
- Spain

Order Unit: 1 Piece


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Head Diameter (mm)	Head Length (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
837-0319	TAH3625W-35	¥12,604	¥15,710	35	100	300	1	500

Snap-On Tools JAPAN K.K.

Contact us: 03-5534-1301 <http://www.snapon.co.jp/>

OH Stock 688 Items

Soft Hammer FP Part II

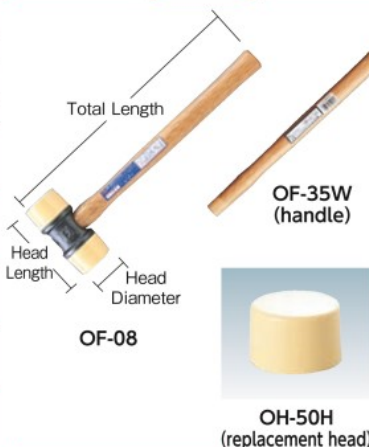

OF-08

OF-35W (handle)

OH-50H (replacement head)

- Features**
- There is a strike force since the head body uses iron.
- Materials**
- Head: Soft polyvinyl chloride (PVC)
 - Handle: Oak
- Origin**
- Japan

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Designation	Head Diameter (mm)	Head Length (mm)	Total Length (mm)	SPQ (piece)	Weight (kg)
123-3891	OF-012	¥2,037	¥2,200	1/4 Pound	18	70	280	6	0.15
123-3904	OF-02	¥2,138	¥2,310	1/2 Pound	23	80	300	6	0.25
123-3912	OF-03	¥2,509	¥2,710	3/4 Pound	33	95	300	6	0.34
123-3921	OF-05	¥2,758	¥2,980	1 Pound	33	113	330	6	0.54
123-3939	OF-08	¥3,805	¥4,110	1 1/2 Pound	48	111	350	6	0.82
123-3947	OF-10	¥4,425	¥4,780	2 Pound	48	117	350	6	1.05
123-3955	OF-135	¥5,573	¥6,020	3 Pound	48	145	360	6	1.35
123-3963	OF-185	¥7,397	¥7,990	4 Pound	62	127	375	6	1.90

O.H.INDUSTRIAL Co.Ltd.

Replacement Head

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Head Diameter (mm)	SPQ (piece)	Weight (g)
123-4064	OH-20H	¥ 352	¥ 380	18	20	5
123-4072	OH-25H	¥ 389	¥ 420	23	20	10
123-4081	OH-35H	¥ 509	¥ 550	33	10	29
123-4099	OH-50H	¥ 852	¥ 920	48	10	63
123-4102	OH-65H	¥1,203	¥1,300	62	10	106

Handle

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Compatible Hammer Designation (pound)	Compatible Model	Weight (g)
356-9331	OF-30W	¥1,102	¥1,190	1/2	OF-02	73
356-9349	OF-31W	¥1,102	¥1,190	3/4	OF-03	77
356-9357	OF-33W	¥1,306	¥1,410	1	OF-05	122
356-9373	OF-35W	¥1,462	¥1,580	1 1/2, 2	OF-08, OF-10	154
356-9381	OF-36W	¥2,138	¥2,310	3	OF-135	175
356-9390	OF-375W	¥2,398	¥2,590	4	OF-185	180

SPQ: 1 Piece

URL <http://www.ohnet.co.jp/>