



Numeral Stamp



Number font

Numeral Stamp 0 to 8, (10 pieces set)

0 1 2 3 4 5 6 7 8 .

Note: Since the numbers 6 and 9 can be multi-usable, add "*" instead of 9, to make it 10 piece set

Stamp Dimension

Character Dimension	Min Stamp Dimension a x b (mm)	Max Stamp Dimension c x d (mm)	Character Dimension	Min Stamp Dimension a x b (mm)	Max Stamp Dimension c x d (mm)
1.5mm	1.5 x 0.97	3.1 x 2.5	6.0mm	6.0 x 4.0	8.2 x 6.2
2.0mm	2.0 x 1.3	3.8 x 3.1	8.0mm	8.0 x 5.4	10.7 x 8.1
2.5mm	2.5 x 1.6	4.3 x 3.4	10.0mm	10.0 x 6.6	12.7 x 9.3
3.0mm	3.0 x 2.0	4.8 x 3.8	13.0mm	13.0 x 8.7	16.1 x 11.8
4.0mm	4.0 x 2.7	5.8 x 4.5	16.0mm	16.0 x 10.8	17.4 x 12.2
5.0mm	5.0 x 3.3	7.0 x 5.3	-	-	-


*The dimensions are rough. Somewhat change. The maximum character size is the maximum dimension character depth. Not a dimension that can be embossed. (Depending on the engraving opponent, you can not emboss to the maximum dimension.) (Characters with stamp at the center of engraving such as "X" "Y" "8" etc. may be hard to reproduce the lines in the center due to the characteristics of the production.)

Material that can be embossed

Aluminum Material	Brass Material	Copper
Not Quenched SS Material	Not Quenched SC Material	Not Quenched SKS Material
Not Quenched SKD Material	Not Quenched SKH Material	Not Quenched SUS Material

Material that can not be embossed

Quenched SS Material	Quenched SC Material	Quenched SKS Material
Quenched SKD Material	Quenched SKH Material	Quenched SUS Material
Carbide Glass	Stone	Rubber
Cloth	Paper	Acrylic

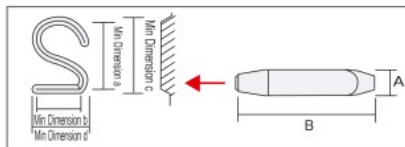

*The stamping of a material with high hardness is exhausted, it may not be possible to emboss.

*The dimension origin of the stamp is the upper and lower center line (minimum dimension a). (shank) Not the size.

Shank Dimension

Characters	Materials Dimension A x B (mm)	Characters	Materials Dimension A x B (mm)
1.5mm	6 x 65	6.0mm	13 x 80
2.0mm	6 x 65	8.0mm	13 x 80
2.5mm	6 x 65	10.0mm	16 x 90
3.0mm	8 x 68	13.0mm	16 x 90
4.0mm	10 x 70	16.0mm	19 x 90
5.0mm	10 x 70	-	-



Stock
38,650
Items

Numral Stamping Set

RoHS




Features •The engraving is deep and the shank is also thick, beautiful letters are stamped and it is an stamped mark that lasts long.

Materials •Carbon Steel (S45C) Tip Quenching

Set Contents •Since the numbers 6 and 9 can be multi-usable, add "*" instead of 9 to made it is 10 pieces per set

Origin •Japan

Actual Size

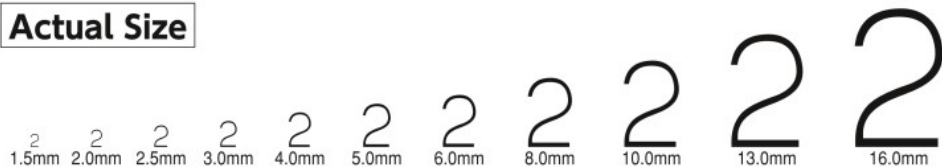

Numeral Stamp[0 to 8 •] (10 pieces set)

0 1 2 3 4 5 6 7 8 .

Order Unit: 1 Set

(Price revision date: Jan, 2018) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per set)	MSRP (per set)	Dimension (mm)	Set Contents (piece)	SPQ (set)	Weight (kg/set)
228-4715	SK-15	¥ 2,758	¥ 2,980	1.5	10	1	0.20
228-4723	SK-20	¥ 2,758	¥ 2,980	2.0	10	1	0.20
228-4731	SK-25	¥ 2,758	¥ 2,980	2.5	10	1	0.20
228-4740	SK-30	¥ 2,981	¥ 3,220	3.0	10	1	0.35
228-4758	SK-40	¥ 3,333	¥ 3,600	4.0	10	1	0.56
228-4766	SK-50	¥ 3,610	¥ 3,900	5.0	10	1	0.56
228-4774	SK-60	¥ 5,064	¥ 5,470	6.0	10	1	1.04
228-4782	SK-80	¥ 6,665	¥ 7,200	8.0	10	1	1.05
228-4791	SK-100	¥ 9,738	¥ 10,520	10.0	10	1	1.76
228-4804	SK-130	¥ 13,719	¥ 14,820	13.0	10	1	1.81
228-4812	SK-160	¥ 32,039	¥ 34,610	16.0	10	1	2.52

Numeral Reverse Character Stamp[0 to 8 •] (10 pieces set)

0 1 2 3 4 5 6 7 8 .

Order Unit: 1 Set

(Price revision date: Jan, 2018)

Order Code	Item No.	Price (per set)	MSRP (per set)	Dimension (mm)	Set Contents (piece)	SPQ (set)	Weight (kg/set)
228-5037	SKB-15	¥ 9,655	¥ 10,430	1.5	10	1	0.20
228-5045	SKB-20	¥ 9,655	¥ 10,430	2.0	10	1	0.20
228-5053	SKB-25	¥ 9,655	¥ 10,430	2.5	10	1	0.20
228-5061	SKB-30	¥ 10,562	¥ 11,410	3.0	10	1	0.35
228-5070	SKB-40	¥ 11,479	¥ 12,400	4.0	10	1	0.56
228-5088	SKB-50	¥ 12,626	¥ 13,640	5.0	10	1	0.56
228-5096	SKB-60	¥ 14,219	¥ 15,360	6.0	10	1	1.04
228-5100	SKB-80	¥ 16,858	¥ 18,210	8.0	10	1	1.05
228-5118	SKB-100	¥ 20,699	¥ 22,360	10.0	10	1	1.76
228-5126	SKB-130	¥ 25,855	¥ 27,930	13.0	10	1	1.81



SK-100



Correct Character



SKB-100



Inverted Letter

Contact us:0120-509-849 <http://www.orange-book.com/>