

Prices displayed include 8% tax.

TRUSCO Stock 38,650 Items

Pin Punch



TPP30



TPP148 (set)

- Features • Optimum for removing tapered pin and spring pin.
 Specs • Octagonal body type • Tip hardness: HRC50±2 (TPP25, TPP30), HRC56±2 (TPP40 to 100)
 • Striking surface hardness: HRC38 to 46
 Materials • Nickel/Chrome/Molybdenum Steel Origin • Taiwan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Width (mm)	Tip Diameter (mm)	SPQ (piece)	Weight (g)
366-9084	TPP25	¥361	¥390	150	10	2.5	20	70
366-9092	TPP30	¥361	¥390	150	10	3.0	20	70
366-9106	TPP40	¥361	¥390	150	10	4.0	20	66
366-9114	TPP45	¥361	¥390	150	10	4.5	20	68
366-9122	TPP50	¥361	¥390	150	10	5.0	20	70
366-9131	TPP55	¥361	¥390	150	10	5.5	20	71
366-9149	TPP60	¥361	¥390	150	10	6.0	20	63
366-9157	TPP70	¥361	¥390	150	10	7.0	20	78
366-9165	TPP80	¥399	¥430	150	12	8.0	20	82
366-9068	TPP100	¥399	¥430	150	12	10.0	20	123

Set


Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
366-9076	TPP148	¥2,638	¥2,850	2.5, 3.0, 4.0, 5.0, 6.0, 7.0, 8.0, 10.0	8	5	650

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

Pin Punch with grip

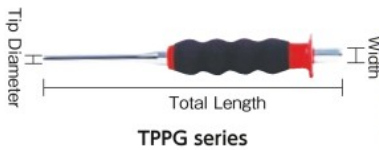

TPPG series

- Features • Increased ease of grip and alleviated fatigue with a handle.
 Origin • Taiwan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Width (mm)	Tip Diameter (mm)	SPQ (piece)	Weight (g)
836-8810	TPPG-25	¥435	¥470	140	8	2.5	20	52
836-8811	TPPG-30	¥435	¥470	150	8	3.0	20	53
836-8812	TPPG-40	¥435	¥470	180	10	4.0	20	96
836-8813	TPPG-45	¥454	¥490	180	10	4.5	20	101
836-8814	TPPG-50	¥454	¥490	200	10	5.0	20	107
836-8815	TPPG-55	¥555	¥600	200	10	5.5	20	112
836-8816	TPPG-60	¥648	¥700	210	12	6.0	20	160
836-8817	TPPG-70	¥648	¥700	210	12	7.0	20	160
836-8818	TPPG-80	¥741	¥800	220	12	8.0	20	173
836-8819	TPPG-100	¥926	¥1,000	230	14	10.0	20	244

Set

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	SPQ (set)	Weight (g/set)
836-8820	TPPG-148	¥4,443	¥4,800	2.5, 3.0, 4.0, 5.0, 6.0, 7.0, 8.0, 10.0	5	1300

Contact us: 0120-509-849 <http://www.orange-book.com/>

MOKUBA Stock 148 Items

Pin Punch



E9-5.0



E14-8 (set)

- Features • Optimum for removing tapered pin and spring pin.
 Specs • Chrome Plate Materials • Carbon Steel Origin • Japan

Order Unit: 1 Piece

KOYAMA EDGED-TOOL WORKS Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Width (mm)	Tip Outer Diameter (mm)	SPQ (piece)	Weight (g)
485-0971	E-9-2	¥363	¥430	150	9.52	2.0	12	80
218-2246	E9-2.5	¥363	¥430	150	9.52	2.5	12	80
218-2254	E9-3	¥363	¥430	150	9.52	3.0	12	80
218-2262	E9-4.0	¥363	¥430	150	9.52	4.0	12	80
218-2271	E9-4.5	¥363	¥430	150	9.52	4.5	12	80
218-2289	E9-5.0	¥363	¥430	150	9.52	5.0	12	80
218-2297	E9-5.5	¥363	¥430	150	9.52	5.5	12	80
218-2301	E9-6.0	¥363	¥430	150	9.52	6.0	12	80
218-2319	E9-7.0	¥363	¥430	150	9.52	7.0	12	80
218-2327	E9-8.0	¥401	¥475	150	12.70	8.0	12	120
218-2335	E9-10.0	¥401	¥475	150	12.70	10.0	12	120

Set

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
327-1374	E14-8	¥2,669	¥3,145	2.5, 3.0, 4.0, 5.0, 6.0, 7.0, 8.0, 10.0	8	6	640

Contact us: 0794-82-5149 <http://www.mokuba-tools.co.jp/>

Hammers • Punches

Single-Ended Hammers

Double-Ended Hammers

Combination Hammers

Shock-Less Hammers

Resin Hammers • Rubber Hammers

Nonferrous Hammers

Stainless Steel Hammers

Wood Hammers

Stone Hammers

Welding Hammers

Sheet Metal Hammers

Claw Hammers

Centering Hammers

Hammers for Woodwork

Hammers for Electric Work

Test Hammers

Wedges

Grip Tapes

Bars

Chisels

Stamps

Date Marks

Industrial Stamps

Punches