

Truss Head Machine Screws

Stock 792 Items

2-449

Prices displayed include 8% tax.



Stock 38,650 Items


Truss Head Machine Screw (steel, full thread type)



B704 Type



- Features**
- A trivalent chromate product with minimal environmental impact.
 - Since the head diameter is large, it is suitable for large screw holes.
 - The height of the head is low, therefore underhead of the slot or cross recess may be slightly fragile.
- Specs**
- Tensile Strength Rank: 4.8
- Materials**
- Low Carbon Steel (SWCH)
 - Surface Treatment: Trivalent Chromate Finishing (white)
- Origin**
- Japan

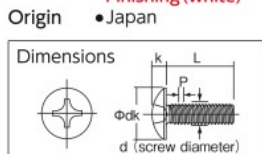

Compatible Screwdriver	
M3	Plus No. 1
M4/M5	Plus No. 2
M6	Plus No. 3

Basic Dimension (unit: mm)

Nominal Designation of Thread (d)	Thread Pitch P	Cross Recess Number	Head Outer Diameter	Head Thickness
			dk	k
M3	0.5	1	6.9	1.9
M4	0.7	2	9.4	2.5
M5	0.8	2	11.8	3.1
M6	1.0	3	14.0	3.7

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
285-5577	B704-0304	¥602	¥650	M3 x 4	173	10	103.8
285-5585	B704-0305	¥602	¥650	M3 x 5	190	10	119.7
285-5593	B704-0306	¥602	¥650	M3 x 6	194	10	130.5
285-5607	B704-0308	¥602	¥650	M3 x 8	185	10	140.2
285-5615	B704-0310	¥602	¥650	M3 x 10	170	10	143.3
285-5623	B704-0312	¥602	¥650	M3 x 12	146	10	135.6
285-5631	B704-0315	¥602	¥650	M3 x 15	134	10	136.6
285-5640	B704-0316	¥602	¥650	M3 x 16	134	10	147.1
285-5658	B704-0320	¥602	¥650	M3 x 20	122	10	154.8
285-5666	B704-0325	¥602	¥650	M3 x 25	90	10	133.2
285-5674	B704-0330	¥602	¥650	M3 x 30	80	10	135.5
285-5682	B704-0405	¥602	¥650	M4 x 5	104	10	135.2
285-5691	B704-0406	¥602	¥650	M4 x 6	122	10	170.6
285-5704	B704-0408	¥602	¥650	M4 x 8	116	10	179.1
285-5712	B704-0410	¥602	¥650	M4 x 10	109	10	184.7
285-5721	B704-0412	¥602	¥650	M4 x 12	104	10	191.9
285-5739	B704-0415	¥602	¥650	M4 x 15	85	10	169.5
285-5747	B704-0416	¥602	¥650	M4 x 16	82	10	175.9
285-5755	B704-0420	¥602	¥650	M4 x 20	68	10	166.3
285-5763	B704-0425	¥602	¥650	M4 x 25	58	10	163.5
285-5771	B704-0430	¥602	¥650	M4 x 30	49	10	156.6
285-5780	B704-0435	¥602	¥650	M4 x 35	43	10	153.5
285-5798	B704-0440	¥602	¥650	M4 x 40	38	10	146.1
285-5801	B704-0445	¥602	¥650	M4 x 45	33	10	142.5
285-5810	B704-0450	¥602	¥650	M4 x 50	29	10	132.2

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
285-5828	B704-0506	¥602	¥650	M5 x 6	65	10	169.0
285-5836	B704-0508	¥602	¥650	M5 x 8	70	10	199.2
285-5844	B704-0510	¥602	¥650	M5 x 10	66	10	203.8
285-5852	B704-0512	¥602	¥650	M5 x 12	64	10	213.0
285-5861	B704-0515	¥602	¥650	M5 x 15	55	10	198.0
285-5879	B704-0516	¥602	¥650	M5 x 16	53	10	201.9
285-5887	B704-0520	¥602	¥650	M5 x 20	48	10	206.1
285-5895	B704-0525	¥602	¥650	M5 x 25	43	10	210.4
285-5909	B704-0530	¥602	¥650	M5 x 30	35	10	192.3
285-5917	B704-0535	¥602	¥650	M5 x 35	22	10	134.1
285-5925	B704-0540	¥602	¥650	M5 x 40	21	10	140.7
285-5933	B704-0545	¥602	¥650	M5 x 45	20	10	146.0
285-5941	B704-0550	¥602	¥650	M5 x 50	19	10	150.1
285-5950	B704-0610	¥602	¥650	M6 x 10	45	10	233.7
285-5968	B704-0612	¥602	¥650	M6 x 12	41	10	226.7
285-5976	B704-0615	¥602	¥650	M6 x 15	37	10	222.0
285-5984	B704-0616	¥602	¥650	M6 x 16	36	10	224.1
285-5992	B704-0620	¥602	¥650	M6 x 20	32	10	221.2
285-6000	B704-0625	¥602	¥650	M6 x 25	28	10	216.5
285-6018	B704-0630	¥602	¥650	M6 x 30	24	10	207.2
285-6026	B704-0635	¥602	¥650	M6 x 35	21	10	199.4
285-6034	B704-0640	¥602	¥650	M6 x 40	19	10	196.7
285-6042	B704-0645	¥602	¥650	M6 x 45	17	10	190.6
285-6051	B704-0650	¥602	¥650	M6 x 50	16	10	193.1

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items


Truss Head Machine Screw (steel, full thread type)




B04 Type



- Features**
- Since the head diameter is large, it is suitable for large screw holes.
- Specs**
- Tensile Strength Rank: 4.8
- Materials**
- Low Carbon Steel (SWCH)
 - Surface Treatment: Unichrome Plated Finishing
- Origin**
- Japan

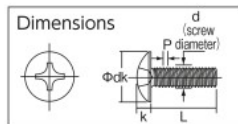

Compatible Screwdriver	
M3	Plus No. 1
M4/M5	Plus No. 2
M6/M8	Plus No. 3

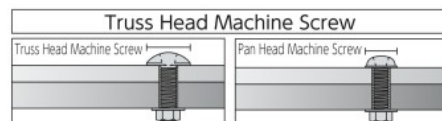

Since the head is wider than the pan head machine screw, firmly presses down the surface.

Basic Dimension (unit: mm)

Nominal Designation of Thread (d)	Thread Pitch P	Cross Recess Number	Head Outer Diameter	Head Thickness
			dk	k
M3	0.50	1	6.9	1.9
M4	0.70	2	9.4	2.5
M5	0.80	2	11.8	3.1
M6	1.00	3	14.0	3.7
M8	1.25	3	17.8	4.8

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
212-6222	B04-0305	¥602	¥650	M3 x 5	260	10	163.8
159-2823	B04-0306	¥602	¥650	M3 x 6	280	10	188.4
159-2831	B04-0308	¥602	¥650	M3 x 8	310	10	234.9
159-2840	B04-0310	¥602	¥650	M3 x 10	290	10	244.4
159-2866	B04-0315	¥602	¥650	M3 x 15	250	10	262.5
212-6311	B04-0405	¥602	¥650	M4 x 5	140	10	185.3
159-2939	B04-0406	¥602	¥650	M4 x 6	175	10	243.9
159-2947	B04-0408	¥602	¥650	M4 x 8	210	10	324.2
159-2955	B04-0410	¥602	¥650	M4 x 10	200	10	339.0
159-2963	B04-0412	¥602	¥650	M4 x 12	180	10	332.1
159-2971	B04-0415	¥602	¥650	M4 x 15	160	10	329.6
159-2998	B04-0420	¥602	¥650	M4 x 20	140	10	342.3
159-3005	B04-0425	¥602	¥650	M4 x 25	120	10	338.4
212-6354	B04-0506	¥602	¥650	M5 x 6	120	10	321.6
159-3064	B04-0508	¥602	¥650	M5 x 8	125	10	355.8
159-3072	B04-0510	¥602	¥650	M5 x 10	125	10	386.0
159-3081	B04-0512	¥602	¥650	M5 x 12	110	10	366.1
159-3099	B04-0515	¥602	¥650	M5 x 15	100	10	373.0

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
159-3111	B04-0520	¥602	¥650	M5 x 20	90	10	386.2
159-3129	B04-0525	¥602	¥650	M5 x 25	75	10	367.1
159-3137	B04-0530	¥602	¥650	M5 x 30	65	10	357.3
212-6397	B04-0608	¥602	¥650	M6 x 8	75	10	363.1
159-3188	B04-0610	¥602	¥650	M6 x 10	70	10	363.5
159-3196	B04-0612	¥602	¥650	M6 x 12	75	10	414.7
159-3200	B04-0615	¥602	¥650	M6 x 15	70	10	424.2
159-3226	B04-0620	¥602	¥650	M6 x 20	65	10	449.2
159-3234	B04-0625	¥602	¥650	M6 x 25	55	10	427.5
159-3242	B04-0630	¥602	¥650	M6 x 30	50	10	431.6
159-3251	B04-0635	¥602	¥650	M6 x 35	45	10	427.1
159-3293	B04-0815	¥602	¥650	M8 x 15	30	10	390.3
159-3315	B04-0820	¥602	¥650	M8 x 20	25	10	364.7
159-3323	B04-0825	¥602	¥650	M8 x 25	25	10	403.7
159-3331	B04-0830	¥602	¥650	M8 x 30	22	10	389.6
159-3340	B04-0835	¥602	¥650	M8 x 35	20	10	385.4
159-3358	B04-0840	¥602	¥650	M8 x 40	18	10	374.9

Contact us: 0120-509-849 <http://www.orange-book.com/>