

Countersunk Machine Screws

Stock 792 Items

2-451

Screws • Bolts • Nuts

Prices displayed include 8% tax.

TRUSCO Stock 38,650 Items

Countersunk Head Machine Screw (steel/full thread type)




- Features • Suitable for work that needs to submerge the head.
 Specs • Tensile Strength Rank: 4.8
 Materials • Low Carbon Steel (SWCH)
 Origin • Japan

Compatible Screwdriver	
M3 to M5	Plus No. 2
M6/M8	Plus No. 3
M10	Plus No. 4



B702 Type

B02 Type

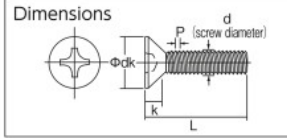

Basic Dimension

Nominal Designation of Thread (d)	Thread Pitch P	Cross Recess Number	Head Outer Diameter (unit: mm)	
			dk	k
M3	0.50	2	6	1.75
M4	0.70	2	8	2.30
M5	0.80	2	10	2.80
M6	1.00	3	12	3.40
M8	1.25	3	16	4.40
M10	1.50	4	20	5.70

Trivalent Chromate Materials • Surface Treatment: Trivalent Chromate Finishing (white)

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
285-4937	B702-0305	¥602	¥650	M3 x 5	204	10	75.3
285-4945	B702-0306	¥602	¥650	M3 x 6	255	10	105.1
285-4953	B702-0308	¥602	¥650	M3 x 8	240	10	119.3
285-4961	B702-0310	¥602	¥650	M3 x 10	214	10	124.5
285-4970	B702-0312	¥602	¥650	M3 x 12	194	10	129.6
285-4988	B702-0315	¥602	¥650	M3 x 15	160	10	125.6
285-4996	B702-0316	¥602	¥650	M3 x 16	148	10	123.9
285-5003	B702-0320	¥602	¥650	M3 x 20	134	10	135.0
285-5011	B702-0325	¥602	¥650	M3 x 25	115	10	140.3
285-5020	B702-0330	¥602	¥650	M3 x 30	90	10	128.9
285-5038	B702-0335	¥602	¥650	M3 x 35	67	10	110.2
285-5046	B702-0340	¥602	¥650	M3 x 40	58	10	107.8
285-5054	B702-0406	¥602	¥650	M4 x 6	122	10	87.1
285-5062	B702-0408	¥602	¥650	M4 x 8	143	10	123.6
285-5071	B702-0410	¥602	¥650	M4 x 10	143	10	145.1
285-5089	B702-0412	¥602	¥650	M4 x 12	136	10	158.5
285-5097	B702-0415	¥602	¥650	M4 x 15	110	10	154.0
285-5101	B702-0416	¥602	¥650	M4 x 16	107	10	156.7
285-5119	B702-0420	¥602	¥650	M4 x 20	87	10	153.6
285-5127	B702-0425	¥602	¥650	M4 x 25	75	10	160.5
285-5135	B702-0430	¥602	¥650	M4 x 30	63	10	158.5
285-5143	B702-0435	¥602	¥650	M4 x 35	54	10	152.3
285-5151	B702-0440	¥602	¥650	M4 x 40	47	10	153.5
285-5160	B702-0445	¥602	¥650	M4 x 45	42	10	152.9
285-5178	B702-0450	¥602	¥650	M4 x 50	41	10	164.7
285-5186	B702-0455	¥602	¥650	M4 x 55	28	10	137.2
285-5194	B702-0460	¥602	¥650	M4 x 60	25	10	130.1
285-5208	B702-0465	¥602	¥650	M4 x 65	23	10	133.4
285-5216	B702-0470	¥602	¥650	M4 x 70	21	10	133.4
285-5224	B702-0475	¥602	¥650	M4 x 75	19	10	131.1
285-5232	B702-0508	¥602	¥650	M5 x 8	68	10	114.4
285-5241	B702-0510	¥602	¥650	M5 x 10	76	10	146.1

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
285-5259	B702-0512	¥602	¥650	M5 x 12	83	10	179.6
285-5267	B702-0515	¥602	¥650	M5 x 15	71	10	177.5
285-5275	B702-0516	¥602	¥650	M5 x 16	68	10	179.9
285-5283	B702-0520	¥602	¥650	M5 x 20	62	10	193.6
285-5291	B702-0525	¥602	¥650	M5 x 25	54	10	201.4
285-5305	B702-0530	¥602	¥650	M5 x 30	45	10	194.9
285-5313	B702-0535	¥602	¥650	M5 x 35	35	10	172.7
285-5321	B702-0540	¥602	¥650	M5 x 40	31	10	171.6
285-5330	B702-0545	¥602	¥650	M5 x 45	28	10	171.8
285-5348	B702-0550	¥602	¥650	M5 x 50	25	10	168.5
285-5356	B702-0555	¥602	¥650	M5 x 55	20	10	146.0
285-5364	B702-0560	¥602	¥650	M5 x 60	19	10	148.2
285-5372	B702-0565	¥602	¥650	M5 x 65	17	10	139.4
285-5381	B702-0570	¥602	¥650	M5 x 70	15	10	117.0
285-5399	B702-0575	¥602	¥650	M5 x 75	13	10	110.0
285-5402	B702-0608	¥602	¥650	M6 x 8	51	10	143.4
285-5411	B702-0610	¥602	¥650	M6 x 10	53	10	167.1
285-5429	B702-0612	¥602	¥650	M6 x 12	54	10	189.0
285-5437	B702-0615	¥602	¥650	M6 x 15	49	10	200.0
285-5445	B702-0616	¥602	¥650	M6 x 16	46	10	192.6
285-5453	B702-0620	¥602	¥650	M6 x 20	42	10	204.7
285-5461	B702-0625	¥602	¥650	M6 x 25	36	10	206.3
285-5470	B702-0630	¥602	¥650	M6 x 30	32	10	210.9
285-5488	B702-0635	¥602	¥650	M6 x 35	28	10	208.6
285-5496	B702-0640	¥602	¥650	M6 x 40	25	10	207.7
285-5500	B702-0645	¥602	¥650	M6 x 45	19	10	174.2
285-5518	B702-0650	¥602	¥650	M6 x 50	18	10	180.5
285-5526	B702-0655	¥602	¥650	M6 x 55	16	10	174.2
285-5534	B702-0660	¥602	¥650	M6 x 60	14	10	165.0
285-5542	B702-0665	¥602	¥650	M6 x 65	13	10	162.5
285-5551	B702-0670	¥602	¥650	M6 x 70	12	10	160.8
285-5569	B702-0675	¥602	¥650	M6 x 75	11	10	156.2

Unichrome Materials • Surface Treatment: Trivalent Chrome Plated Finishing

Order Unit: 1 Bag

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
159-1321	B02-0305	¥602	¥650	M3 x 5	380	10	140.2
159-1339	B02-0306	¥602	¥650	M3 x 6	400	10	164.8
159-1347	B02-0308	¥602	¥650	M3 x 8	360	10	178.9
159-1355	B02-0310	¥602	¥650	M3 x 10	360	10	209.5
159-1363	B02-0312	¥602	¥650	M3 x 12	300	10	200.4
159-1371	B02-0315	¥602	¥650	M3 x 15	300	10	240.0
159-1398	B02-0320	¥602	¥650	M3 x 20	240	10	241.9
159-1461	B02-0406	¥602	¥650	M4 x 6	260	10	185.6
159-1479	B02-0408	¥602	¥650	M4 x 8	260	10	224.6
159-1487	B02-0410	¥602	¥650	M4 x 10	250	10	253.7
159-1495	B02-0412	¥602	¥650	M4 x 12	250	10	291.2
159-1509	B02-0415	¥602	¥650	M4 x 15	200	10	280.0
159-1525	B02-0420	¥602	¥650	M4 x 20	170	10	300.2
159-1533	B02-0425	¥602	¥650	M4 x 25	140	10	299.6
159-1541	B02-0430	¥602	¥650	M4 x 30	120	10	301.9
159-1550	B02-0435	¥602	¥650	M4 x 35	105	10	303.5
159-1568	B02-0440	¥602	¥650	M4 x 40	90	10	293.9
159-1576	B02-0445	¥602	¥650	M4 x 45	85	10	309.4
159-1584	B02-0450	¥602	¥650	M4 x 50	70	10	281.1
159-1606	B02-0460	¥602	¥650	M4 x 60	50	10	235.0
159-1649	B02-0508	¥602	¥650	M5 x 8	165	10	277.5
159-1657	B02-0510	¥602	¥650	M5 x 10	160	10	307.6
159-1665	B02-0512	¥602	¥650	M5 x 12	150	10	324.6
159-1673	B02-0515	¥602	¥650	M5 x 15	130	10	335.4
159-1690	B02-0520	¥602	¥650	M5 x 20	120	10	374.7
159-1703	B02-0525	¥602	¥650	M5 x 25	100	10	373.0
159-1711	B02-0530	¥602	¥650	M5 x 30	80	10	346.5
159-1720	B02-0535	¥602	¥650	M5 x 35	70	10	345.3

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
159-1738	B02-0540	¥602	¥650	M5 x 40	65	10	359.9
159-1754	B02-0550	¥602	¥650	M5 x 50	55	10	370.7
212-7733	B02-0608	¥602	¥650	M6 x 8	100	10	281.2
159-1819	B02-0610	¥602	¥650	M6 x 10	100	10	315.6
159-1827	B02-0612	¥602	¥650	M6 x 12	100	10	350.0
159-1835	B02-0615	¥602	¥650	M6 x 15	90	10	361.8
159-1851	B02-0620	¥602	¥650	M6 x 20	80	10	389.9
159-1878	B02-0625	¥602	¥650	M6 x 25	65	10	372.6
159-1886	B02-0630	¥602	¥650	M6 x 30	60	10	395.5
159-1894	B02-0635	¥602	¥650	M6 x 35	55	10	409.8
159-1908	B02-0640	¥602	¥650	M6 x 40	50	10	415.5
159-1924	B02-0650	¥602	¥650	M6 x 50	40	10	401.2
159-1941	B02-0660	¥602	¥650	M6 x 60	25	10	294.7
159-1983	B02-0815	¥602	¥650	M8 x 15	35	10	304.5
159-2009	B02-0820	¥602	¥650	M8 x 20	33	10	318.3
159-2017	B02-0825	¥602	¥650	M8 x 25	33	10	389.7
159-2025	B02-0830	¥602	¥650	M8 x 30	30	10	401.1
159-2033	B02-0835	¥602	¥650	M8 x 35	27	10	403.1
159-2041	B02-0840	¥602	¥650	M8 x 40	23	10	379.2
159-2050	B02-0845	¥602	¥650	M8 x 45	21	10	379.0
159-2068	B02-0850	¥602	¥650	M8 x 50	19	10	372.5
212-7806	B02-1020	¥602	¥650	M10 x 20	15	10	213.0
212-7814	B02-1025	¥602	¥650	M10 x 25	12	10	192.0
212-7822	B02-1030	¥602	¥650	M10 x 30	11	10	213.4
212-7831	B02-1035	¥602	¥650	M10 x 35	10	10	215.0
212-7849	B02-1040	¥602	¥650	M10 x 40	9	10	220.5
212-7857	B02-1045	¥602	¥650	M10 x 45	8	10	216.0
212-7865	B02-1050	¥602	¥650	M10 x 50	7	10	210.0

Contact us: 0120-509-849 <http://www.orange-book.com/>