

Pan Head Tapping Screws

For Drill Screwdriver, see p. 5-124 to 156

The number next to the logo mark indicates items in stock for each brand.



Stock
38,650
Items

Pan Head Tapping Screw




B707 Type
(steel (trivalent chrome))

B07 Type
(steel (unichrome))

B09 Type
(stainless steel)

Features • A screw for thin steel plate which can be fastened with a pilot hole only without using a tap or nut.

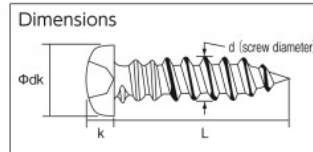

Basic Dimension
(unit: mm)

Head Outer Diameter (Φdk)	Head Thickness (k)	Screw Pilot Hole Dimension
M3	5.5	2.0
M4	7.0	2.6
M5	9.0	3.3
M6	10.5	3.9

*The screw pilot hole dimension is in case of the base material thickness of 1.2mm.

Steel (trivalent chrome)

Features • A trivalent chrome product with minimal environmental impact.

Materials • Low Carbon Steel (SWCH)

• Surface Treatment: Trivalent Chrome Finishing (white)

Origin • Japan

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
285-6069	B707-0306	¥602	¥650	M3 x 6	173	10	73.5
285-6077	B707-0308	¥602	¥650	M3 x 8	163	10	82.5
285-6085	B707-0310	¥602	¥650	M3 x 10	154	10	90.6
285-6093	B707-0312	¥602	¥650	M3 x 12	146	10	97.8
285-6107	B707-0316	¥602	¥650	M3 x 16	123	10	102.5
285-6115	B707-0320	¥602	¥650	M3 x 20	106	10	102.4
285-6123	B707-0325	¥602	¥650	M3 x 25	91	10	109.4
285-6131	B707-0330	¥602	¥650	M3 x 30	71	10	99.4
285-6140	B707-0335	¥602	¥650	M3 x 35	51	10	84.1
285-6158	B707-0340	¥602	¥650	M3 x 40	41	10	73.8
285-6166	B707-0408	¥602	¥650	M4 x 8	115	10	110.5
285-6174	B707-0410	¥602	¥650	M4 x 10	109	10	119.9
285-6182	B707-0412	¥602	¥650	M4 x 12	101	10	125.1
285-6191	B707-0416	¥602	¥650	M4 x 16	89	10	134.8
285-6204	B707-0420	¥602	¥650	M4 x 20	78	10	139.6
285-6212	B707-0425	¥602	¥650	M4 x 25	66	10	140.9
285-6221	B707-0430	¥602	¥650	M4 x 30	57	10	141.4
285-6239	B707-0435	¥602	¥650	M4 x 35	49	10	138.4
285-6247	B707-0440	¥602	¥650	M4 x 40	42	10	144.8
285-6255	B707-0445	¥602	¥650	M4 x 45	37	10	142.9
285-6263	B707-0450	¥602	¥650	M4 x 50	32	10	123.6
285-6271	B707-0455	¥602	¥650	M4 x 55	25	10	105.1
285-6280	B707-0460	¥602	¥650	M4 x 60	22	10	103.4
285-6298	B707-0465	¥602	¥650	M4 x 65	19	10	98.8
285-6301	B707-0470	¥602	¥650	M4 x 70	17	10	98.6
285-6310	B707-0475	¥602	¥650	M4 x 75	15	10	96.0
285-6328	B707-0510	¥602	¥650	M5 x 10	58	10	109.6
285-6336	B707-0512	¥602	¥650	M5 x 12	56	10	118.2

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
285-6344	B707-0516	¥602	¥650	M5 x 16	51	10	130.3
285-6352	B707-0520	¥602	¥650	M5 x 20	46	10	137.9
285-6361	B707-0525	¥602	¥650	M5 x 25	40	10	142.0
285-6379	B707-0530	¥602	¥650	M5 x 30	35	10	143.6
285-6387	B707-0535	¥602	¥650	M5 x 35	30	10	139.8
285-6395	B707-0540	¥602	¥650	M5 x 40	26	10	135.6
285-6409	B707-0545	¥602	¥650	M5 x 45	23	10	133.4
285-6417	B707-0550	¥602	¥650	M5 x 50	20	10	126.5
285-6425	B707-0555	¥602	¥650	M5 x 55	17	10	113.9
285-6433	B707-0560	¥602	¥650	M5 x 60	15	10	109.5
285-6441	B707-0565	¥602	¥650	M5 x 65	14	10	112.0
285-6450	B707-0570	¥602	¥650	M5 x 70	12	10	103.2
285-6468	B707-0575	¥602	¥650	M5 x 75	11	10	101.3
285-6476	B707-0610	¥602	¥650	M6 x 10	34	10	116.5
285-6484	B707-0612	¥602	¥650	M6 x 12	35	10	121.4
285-6492	B707-0616	¥602	¥650	M6 x 16	31	10	127.1
285-6506	B707-0620	¥602	¥650	M6 x 20	28	10	132.5
285-6514	B707-0625	¥602	¥650	M6 x 25	26	10	143.6
285-6522	B707-0630	¥602	¥650	M6 x 30	23	10	141.4
285-6531	B707-0635	¥602	¥650	M6 x 35	20	10	142.0
285-6549	B707-0640	¥602	¥650	M6 x 40	17	10	134.2
285-6557	B707-0645	¥602	¥650	M6 x 45	15	10	123.0
285-6565	B707-0650	¥602	¥650	M6 x 50	14	10	132.7
285-6573	B707-0655	¥602	¥650	M6 x 55	12	10	127.2
285-6581	B707-0660	¥602	¥650	M6 x 60	11	10	126.5
285-6590	B707-0665	¥602	¥650	M6 x 65	10	10	120.0
285-6603	B707-0670	¥602	¥650	M6 x 70	9	10	117.9
285-6611	B707-0675	¥602	¥650	M6 x 75	8	10	104.0

Steel (unichrome)

Materials • Low Carbon Steel (SWCH) • Surface Treatment: Unichrome Plated Finishing

Origin • Japan

Order Unit: 1 Bag

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
159-4851	B07-0308	¥602	¥650	M3 x 8	290	10	146.7
159-4869	B07-0310	¥602	¥650	M3 x 10	260	10	152.8
159-4877	B07-0312	¥602	¥650	M3 x 12	250	10	167.5
159-4885	B07-0316	¥602	¥650	M3 x 16	225	10	187.4
159-4893	B07-0320	¥602	¥650	M3 x 20	195	10	194.2
159-4907	B07-0325	¥602	¥650	M3 x 25	160	10	192.0
159-4915	B07-0330	¥602	¥650	M3 x 30	140	10	196.0
159-4958	B07-0410	¥602	¥650	M4 x 10	170	10	187.0
159-4966	B07-0412	¥602	¥650	M4 x 12	160	10	198.0
159-4974	B07-0416	¥602	¥650	M4 x 16	150	10	227.1
159-4982	B07-0420	¥602	¥650	M4 x 20	130	10	232.7
159-4991	B07-0425	¥602	¥650	M4 x 25	110	10	234.8
159-5008	B07-0430	¥602	¥650	M4 x 30	95	10	235.7
159-5016	B07-0435	¥602	¥650	M4 x 35	80	10	226.0
159-5024	B07-0440	¥602	¥650	M4 x 40	70	10	241.2
159-5041	B07-0450	¥602	¥650	M4 x 50	55	10	212.4
159-5067	B07-0460	¥602	¥650	M4 x 60	40	10	186.4
159-5075	B07-0465	¥602	¥650	M4 x 65	38	10	154.2

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
159-5083	B07-0470	¥602	¥650	M4 x 70	34	10	185.6
159-5091	B07-0475	¥602	¥650	M4 x 75	30	10	175.8
159-5113	B07-0510	¥602	¥650	M5 x 10	110	10	207.7
159-5121	B07-0512	¥602	¥650	M5 x 12	100	10	211.1
159-5130	B07-0516	¥602	¥650	M5 x 16	90	10	229.8
159-5148	B07-0520	¥602	¥650	M5 x 20	80	10	239.8
159-5156	B07-0525	¥602	¥650	M5 x 25	70	10	248.6
159-5164	B07-0530	¥602	¥650	M5 x 30	60	10	246.3
159-5172	B07-0535	¥602	¥650	M5 x 35	55	10	256.2
159-5181	B07-0540	¥602	¥650	M5 x 40	50	10	260.7
159-5202	B07-0550	¥602	¥650	M5 x 50	35	10	221.2
159-5288	B07-0616	¥602	¥650	M6 x 16	50	10	205.0
159-5296	B07-0620	¥602	¥650	M6 x 20	45	10	212.9
159-5300	B07-0625	¥602	¥650	M6 x 25	40	10	220.9
159-5318	B07-0630	¥602	¥650	M6 x 30	35	10	215.1
159-5351	B07-0650	¥602	¥650	M6 x 50	21	10	199.0
159-5377	B07-0660	¥602	¥650	M6 x 60	18	10	199.4
159-5385	B07-0665	¥602	¥650	M6 x 65	17	10	201.9

Stainless Steel

Materials • Stainless Steel (SUS304 equivalent material)

Origin • -

Order Unit: 1 Bag

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
159-5431	B09-0310	¥741	¥800	M3 x 10	150	10	88.2
159-5440	B09-0312	¥741	¥800	M3 x 12	140	10	93.8
159-5458	B09-0316	¥741	¥800	M3 x 16	120	10	99.9
159-5466	B09-0320	¥741	¥800	M3 x 20	100	10	99.6
159-5474	B09-0325	¥741	¥800	M3 x 25	85	10	102.0
159-5482	B09-0330	¥741	¥800	M3 x 30	75	10	105.0
159-5491	B09-0408	¥741	¥800	M4 x 8	110	10	105.7
159-5504	B09-0410	¥741	¥800	M4 x 10	100	10	110.0
159-5512	B09-0412	¥741	¥800	M4 x 12	95	10	117.6
159-5521	B09-0416	¥741	¥800	M4 x 16	80	10	121.1
159-5539	B09-0420	¥741	¥800	M4 x 20	70	10	125.3
159-5547	B09-0425	¥741	¥800	M4 x 25	60	10	128.1
159-5555	B09-0430	¥741	¥800	M4 x 30	50	10	124.0
159-5563	B09-0435	¥741	¥800	M4 x 35	45	10	127.1
159-5571	B09-0440	¥741	¥800	M4 x 40	40	10	137.8
159-5580	B09-0445	¥741	¥800	M4 x 45	30	10	114.0
159-5598	B09-0450	¥741	¥800	M4 x 50	25	10	96.5

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
159-5601	B09-0510	¥741	¥800	M5 x 10	60	10	113.3
159-5628	B09-0516	¥741	¥800	M5 x 16	45	10	114.9
159-5636	B09-0520	¥741	¥800	M5 x 20	40	10	119.9
159-5644	B09-0525	¥741	¥800	M5 x 25	35	10	124.3
159-5652	B09-0530	¥741	¥800	M5 x 30	30	10	123.1
159-5661	B09-0535	¥741	¥800	M5 x 35	25	10	116.4
159-5679	B09-0540	¥741	¥800	M5 x 40	22	10	114.7
159-5687	B09-0545	¥741	¥800	M5 x 45	20	10	115.4
159-5695	B09-0550	¥741	¥800	M5 x 50	18	10	113.8
159-5709	B09-0616	¥741	¥800	M6 x 16	30	10	123.0
159-5717	B09-0620	¥741	¥800	M6 x 20	25	10	118.3
159-5725	B09-0625	¥741	¥800	M6 x 25	22	10	121.5
159-5733	B09-0630	¥741	¥800	M6 x 30	20	10	122.9
159-5750	B09-0640	¥741	¥800	M6 x 40	15	10	118.4
159-5776	B09-0650	¥741	¥800	M6 x 50	13	10	123.1