


Prices displayed include 8% tax.



Stock 38,650 Items

Flexible Ratchet Combination Wrench

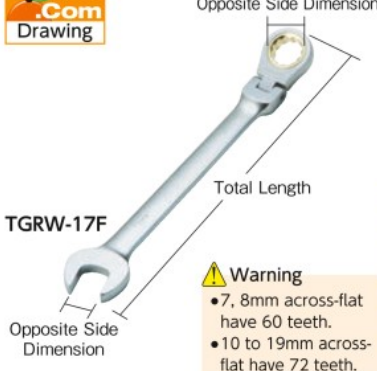

Features

- Switching between normal and reverse is not attached.
- The angle of the head on the ratchet box end side can be set arbitrarily.
- Feed angle 5° has been realized.
- The finish side is beautiful, the touch is good and there is a heavy feeling.
- Surface treatment is trivalent chromium plating.

Warning

- 7, 8mm across-flat have 60 teeth.
- 10 to 19mm across-flat have 72 teeth.

Materials • Chrome Vanadium Steel (Cr-V) **Origin** • Taiwan

Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side Dimension (mm)	Thickness (mm)		Total Length (mm)	SPQ (piece)	Weight (g)
					Spanner	Ring			
415-9934	TGRW-07F	¥1,138	¥1,230	7	5.1	7.0	136	10	39
415-9942	TGRW-08F	¥1,250	¥1,350	8	5.1	7.0	136	10	37
415-9951	TGRW-10F	¥1,416	¥1,530	10	5.7	7.7	160	10	63
415-9969	TGRW-12F	¥1,509	¥1,630	12	6.3	8.7	174	10	89
415-9977	TGRW-13F	¥1,565	¥1,690	13	6.5	9.3	180	10	108
415-9985	TGRW-14F	¥1,722	¥1,860	14	6.8	9.4	193	10	130
415-9993	TGRW-17F	¥2,268	¥2,450	17	7.8	10.9	233	10	214
416-0011	TGRW-19F	¥2,499	¥2,700	19	8.5	11.5	250	10	269

Set Accessories • Storage Pouch

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
416-0029	TGRW-800F	¥13,645	¥14,740	7, 8, 10, 12, 13, 14, 17, 19	8	1	1169



TGRW-800F (when expands) (when in storage)

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items

Head Swing Ratchet Combination Wrench (short type)



Features

- Switching between normal and reverse is not attached.
- The angle of the head on the ratchet box end side can be set arbitrarily.
- Feed angle 5° has been realized.
- The finish side is beautiful, the touch is good and there is a heavy feeling.
- Surface treatment is trivalent chromium plating.

Warning

- 7, 8mm across-flat have 60 teeth.
- 10 to 19mm across-flat have 72 teeth.

Materials • Chrome Vanadium Steel (Cr-V) **Origin** • Taiwan

Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side Dimension (mm)	Thickness (mm)		Total Length (mm)	SPQ (piece)	Weight (g)
					Spanner	Ring			
415-9845	TGRW-07FS	¥ 917	¥ 990	7	5.5	7.0	88	10	32
415-9853	TGRW-08FS	¥1,000	¥1,080	8	5.5	7.0	88	10	31
415-9861	TGRW-10FS	¥1,130	¥1,220	10	6.1	7.7	96	10	46
415-9870	TGRW-12FS	¥1,203	¥1,300	12	6.7	8.7	104	10	69
415-9888	TGRW-13FS	¥1,250	¥1,350	13	7.0	9.3	108	10	79
415-9896	TGRW-14FS	¥1,379	¥1,490	14	7.3	9.4	114	10	96
415-9900	TGRW-17FS	¥1,814	¥1,960	17	8.3	10.9	128	10	150
415-9918	TGRW-19FS	¥1,999	¥2,160	19	9.0	11.5	138	10	188

Set Accessories • Storage Pouch

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
415-9926	TGRW-800FS	¥10,896	¥11,770	7, 8, 10, 12, 13, 14, 17, 19	8	1	891




TGRW-800FS (when opening) (when in storage)

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items

Switch Type Ratchet Combination Wrench

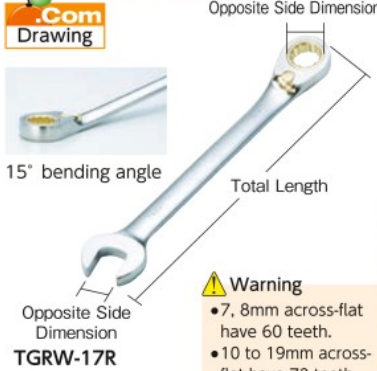

Features

- You can switch between normal and reverse by moving the switching claw left and right.
- The handle part of the ratchet wrench is as small as 15° of turning angle, so it is optimum for the work of the place to receive height restriction.
- Feed angle 5° has been realized.
- The finish side is beautiful, the touch is good and there is a heavy feeling.
- Surface treatment is trivalent chromium plating.

Warning

- 7, 8mm across-flat have 60 teeth.
- 10 to 19mm across-flat have 72 teeth.

Materials • Chrome Vanadium Steel (Cr-V) **Origin** • Taiwan

Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side Dimension (mm)	Thickness (mm)		Total Length (mm)	SPQ (piece)	Weight (g)
					Spanner	Ring			
415-9756	TGRW-07R	¥1,027	¥1,110	7	5.1	7.7	124	10	35
415-9764	TGRW-08R	¥1,130	¥1,220	8	5.1	7.7	135	10	36
415-9772	TGRW-10R	¥1,278	¥1,380	10	5.8	8.2	158	10	56
415-9781	TGRW-12R	¥1,351	¥1,460	12	6.1	8.8	173	10	77
415-9799	TGRW-13R	¥1,416	¥1,530	13	6.6	8.9	179	10	101
415-9802	TGRW-14R	¥1,545	¥1,670	14	7.5	9.3	189	10	119
415-9811	TGRW-17R	¥2,037	¥2,200	17	8.0	10.6	232	10	195
415-9829	TGRW-19R	¥2,240	¥2,420	19	8.9	11.2	247	10	241

Set Accessories • Storage Pouch

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
415-9837	TGRW-800R	¥12,219	¥13,200	7, 8, 10, 12, 13, 14, 17, 19	8	1	1082



TGRW-800R (when expands) (when in storage)

Contact us: 0120-509-849 <http://www.orange-book.com/>