




Stock 38,650 Items


Switching Type Ratchet Combination Wrench (short type)

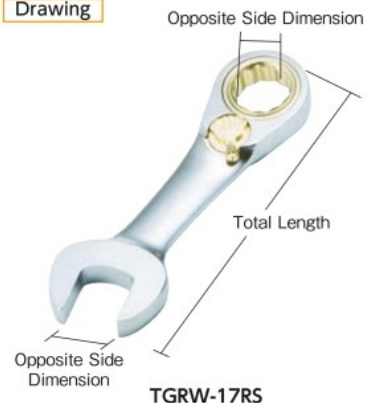

Features • You can switch between normal and reverse by moving the switching claw left and right.

- The handle part of the ratchet wrench is as small as 15° of turning angle, so it is optimum for the work of the place to receive height restriction.
- Feed angle 5° has been realized.
- The finish side is beautiful, the touch is good and there is a heavy feeling.
- Surface treatment is trivalent chromium plating.

Materials • Chrome Vanadium Steel (Cr-V)
Origin • Taiwan

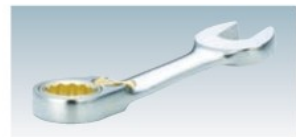

15° bending angle

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side Dimension (mm)	Thickness (mm)		Total Length (mm)	SPQ (piece)	Weight (g)
					Spanner	Ring			
415-9667	TGRW-07RS	¥ 824	¥ 890	7	5.5	7.4	90	10	30
415-9675	TGRW-08RS	¥ 897	¥ 970	8	5.5	7.4	90	10	28
415-9683	TGRW-10RS	¥1,009	¥1,090	10	5.8	7.6	95	10	40
415-9691	TGRW-12RS	¥1,083	¥1,170	12	6.4	8.9	105	10	59
415-9705	TGRW-13RS	¥1,130	¥1,220	13	6.7	9.0	107	10	69
415-9713	TGRW-14RS	¥1,241	¥1,340	14	7.4	9.4	114	10	87
415-9721	TGRW-17RS	¥1,630	¥1,760	17	8.8	10.7	126	10	133
415-9730	TGRW-19RS	¥1,796	¥1,940	19	9.5	11.2	138	10	165

Set Accessories • Storage Pouch

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
415-9748	TGRW-800RS	¥9,535	¥10,300	7, 8, 10, 12, 13, 14, 17, 19	8	1	811

Contact us: 0120-509-849 <http://www.orange-book.com/>




TGRW-800RS (when opening)

(when in storage)



Stock 38,650 Items


Quick Ratchet Combination Wrench

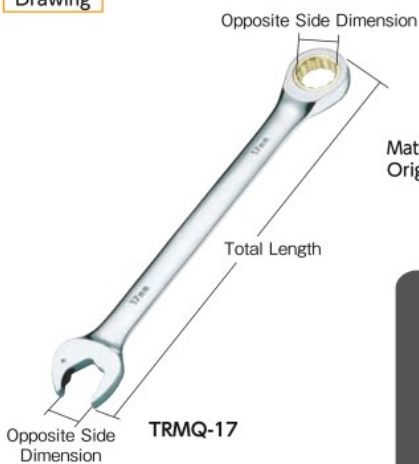

Features • Switching between normal and reverse is not attached.

- Quick turning operation can be performed without removing-inserting of both spanner and spectacle parts.
- Since it is a straight shape, it is optimum for work in narrow places and deep places.
- Feed angle 5° has been realized.
- The finish side is beautiful, the touch is good and there is a heavy feeling.
- Optimum for tightening work in piping flare nuts and narrow places.
- Surface treatment is trivalent chromium plating.

Materials • Chrome Vanadium Steel (Cr-V)
Origin • Taiwan

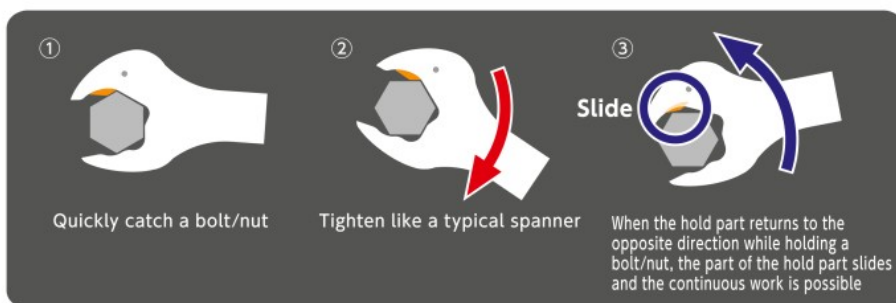

*The direction of ratchet cannot be changed. When loosening a bolt/nut, please use it by turning it over.

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side Dimension (mm)	Thickness (mm)		Total Length (mm)	SPQ (piece)	Weight (g)
					Spanner	Ring			
488-9631	TRMQ-08	¥1,037	¥1,120	8	5.3	7.0	136	10	35
488-9649	TRMQ-10	¥1,083	¥1,170	10	6.1	7.7	160	10	55
488-9657	TRMQ-12	¥1,148	¥1,240	12	7.5	8.7	174	10	79
488-9665	TRMQ-13	¥1,221	¥1,320	13	7.5	9.3	180	10	93
488-9673	TRMQ-14	¥1,314	¥1,420	14	8.3	9.4	193	10	120
488-9681	TRMQ-17	¥1,574	¥1,700	17	9.0	10.9	233	10	188
488-9690	TRMQ-19	¥1,740	¥1,880	19	9.6	11.5	250	10	238

Set Accessories • Storage Pouch

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (kg/set)
488-9703	TRMQ-700	¥9,572	¥10,340	8, 10, 12, 13, 14, 17, 19	7	1	0.98

Contact us: 0120-509-849 <http://www.orange-book.com/>



TRMQ-700 (when opening)

(when in storage)