

# Double Open End Spanners

The number next to the logo mark indicates items in stock for each brand.

Power Wrenches

Ratchet Wrenches

Combination Ratchet Wrenches

Piping Ratchet Wrenches

Flat Ratchet Wrenches

Offset Wrenches

Gear Wrenches

Slugging Wrenches

Flare Nut Wrenches

Crow Foot Wrenches

Monkey Wrenches

Spanners

Combination Spanners

Hook Spanners

Special Purpose Spanners


Gear Pullers

Bearing Pullers



Stock 38,650 Items

## Double-end Wrench

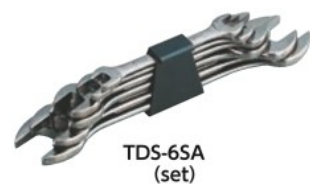

- Features**
- Non-chrome plating (nickel plating) processing, environmentally friendly.
  - The surface is satin finish, easy to fit in and hard to slip specifications.
- Materials**
- Chrome Vanadium Steel (Cr-V)
- Origin**
- Taiwan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Width Across-Flat Dimension (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
301-4819	TDS-0507	¥ 426	¥ 460	5.5 x 7	102	10	20
301-4827	TDS-0607	¥ 426	¥ 460	6.0 x 7	102	10	20
301-4835	TDS-0608	¥ 426	¥ 460	6.0 x 8	102	10	20
301-4843	TDS-0708	¥ 426	¥ 460	7.0 x 8	102	10	20
301-4851	TDS-0809	¥ 417	¥ 450	8.0 x 9	110	10	29
301-4860	TDS-0810	¥ 463	¥ 500	8.0 x 10	110	10	29
301-4878	TDS-1012	¥ 509	¥ 550	10.0 x 12	126	10	42
301-4886	TDS-1013	¥ 509	¥ 550	10.0 x 13	135	10	52
301-4894	TDS-1113	¥ 509	¥ 550	11.0 x 13	135	10	52
301-4908	TDS-1214	¥ 509	¥ 550	12.0 x 14	152	10	80
301-4916	TDS-1317	¥ 528	¥ 570	13.0 x 17	157	10	117
301-4924	TDS-1417	¥ 528	¥ 570	14.0 x 17	157	10	117
301-4932	TDS-1719	¥ 638	¥ 690	17.0 x 19	190	10	155
301-4941	TDS-1921	¥ 768	¥ 830	19.0 x 21	212	5	240
301-4959	TDS-1922	¥ 768	¥ 830	19.0 x 22	212	5	240
301-4967	TDS-1924	¥ 768	¥ 830	19.0 x 24	212	5	240
301-4975	TDS-2123	¥ 917	¥ 990	21.0 x 23	212	5	240
301-4983	TDS-2224	¥ 917	¥ 990	22.0 x 24	212	5	240
301-4991	TDS-2427	¥ 1,074	¥ 1,160	24.0 x 27	257	5	350
301-5009	TDS-2430	¥ 1,324	¥ 1,430	24.0 x 30	285	5	518
301-5017	TDS-2730	¥ 1,583	¥ 1,710	27.0 x 30	340	5	707
301-5025	TDS-3032	¥ 1,648	¥ 1,780	30.0 x 32	340	5	707

Set Accessories • Metal Clip

Order Unit: 1 Set



Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
301-4061	TDS-6SA	¥ 3,360	¥ 3,630	8 x 9, 10 x 12, 12 x 14, 14 x 17, 17 x 19, 21 x 23	6	10	560
301-4070	TDS-6SB	¥ 3,157	¥ 3,410	5.5 x 7, 8 x 10, 11 x 13, 12 x 14, 17 x 19, 22 x 24	6	10	530
301-4088	TDS-6SC	¥ 3,629	¥ 3,920	8 x 9, 10 x 12, 12 x 14, 14 x 17, 19 x 21, 24 x 27	6	10	610
301-4096	TDS-7S	¥ 3,360	¥ 3,630	5.5 x 7, 8 x 9, 10 x 12, 11 x 13, 12 x 14, 14 x 17, 17 x 19	7	10	580

Contact us:0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items

## "Mirror Type Double Open End Spanner"

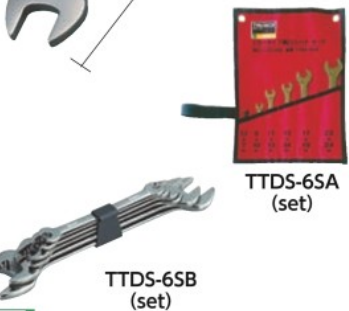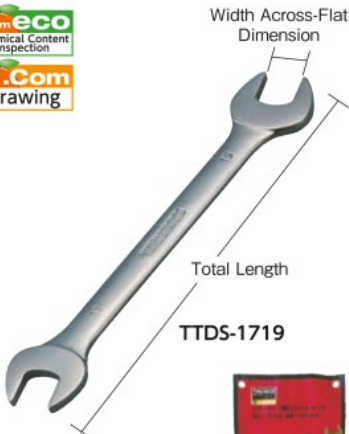

- Features**
- Non-chrome plating (nickel plating) processing, environmentally friendly.
  - The metal surface is beautiful, it is a mirror type with a good weight feeling.
- Materials**
- Chrome Vanadium Steel (Cr-V)
- Origin**
- Taiwan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Width Across-Flat Dimension (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
301-4592	TTDS-0507	¥ 435	¥ 470	5.5 x 7	122	10	11
301-4606	TTDS-0607	¥ 435	¥ 470	6.0 x 7	122	10	25
301-4614	TTDS-0608	¥ 435	¥ 470	6.0 x 8	122	10	25
301-4622	TTDS-0708	¥ 472	¥ 510	7.0 x 8	122	10	25
301-4631	TTDS-0809	¥ 472	¥ 510	8.0 x 9	140	10	32
301-4649	TTDS-0810	¥ 472	¥ 510	8.0 x 10	140	10	32
301-4657	TTDS-1012	¥ 490	¥ 530	10.0 x 12	156	10	48
301-4665	TTDS-1013	¥ 638	¥ 690	10.0 x 13	172	10	63
301-4673	TTDS-1113	¥ 676	¥ 730	11.0 x 13	172	10	63
301-4681	TTDS-1214	¥ 676	¥ 730	12.0 x 14	180	10	85
301-4690	TTDS-1317	¥ 741	¥ 800	13.0 x 17	188	10	96
301-4703	TTDS-1417	¥ 741	¥ 800	14.0 x 17	188	10	96
301-4711	TTDS-1719	¥ 889	¥ 960	17.0 x 19	220	10	171
301-4720	TTDS-1921	¥ 1,018	¥ 1,100	19.0 x 21	234	5	198
301-4738	TTDS-1922	¥ 1,018	¥ 1,100	19.0 x 22	234	5	198
301-4746	TTDS-1924	¥ 1,074	¥ 1,160	19.0 x 24	234	5	200
301-4754	TTDS-2123	¥ 1,074	¥ 1,160	21.0 x 23	247	5	200
301-4762	TTDS-2224	¥ 1,111	¥ 1,200	22.0 x 24	247	5	200
301-4771	TTDS-2427	¥ 1,286	¥ 1,390	24.0 x 27	266	5	311
301-4789	TTDS-2430	¥ 1,630	¥ 1,760	24.0 x 30	285	5	405
301-4797	TTDS-2730	¥ 1,934	¥ 2,090	27.0 x 30	302	5	460
301-4801	TTDS-3032	¥ 1,990	¥ 2,150	30.0 x 32	302	5	460

Set

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Accessories	Set Contents (piece)	SPQ (set)	Weight (g/set)
301-4029	TTDS-6SA	¥ 4,573	¥ 4,940	5.5 x 7, 8 x 10, 11 x 13, 12 x 14, 17 x 19, 22 x 24	Storage pouch	6	10	515
301-4037	TTDS-6SB	¥ 5,045	¥ 5,450	8 x 9, 10 x 12, 12 x 14, 14 x 17, 19 x 21, 24 x 27	Metal Clip	6	10	610
301-4045	TTDS-6SC	¥ 3,870	¥ 4,180	5.5 x 7, 8 x 9, 10 x 12, 11 x 13, 12 x 14, 14 x 17	Resin snake band	6	10	520
301-4053	TTDS-7S	¥ 4,785	¥ 5,170	5.5 x 7, 8 x 9, 10 x 12, 11 x 13, 12 x 14, 14 x 17, 17 x 19	Resin snake band	7	10	710

Contact us:0120-509-849 <http://www.orange-book.com/>