


Prices displayed include 8% tax.



Stock 38,650 Items

Double-end Wrench

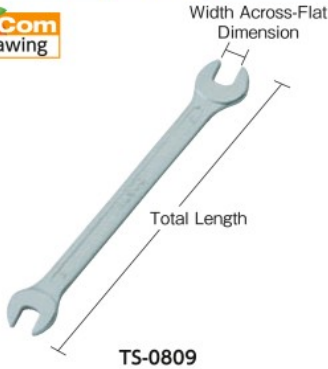

Features • The finish side is beautiful, the touch is good and there is a heavy feeling.

• Surface treatment is trivalent chromium plating.

Materials • Chrome Vanadium Steel (Cr-V) Origin • Taiwan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Width Across-Flat Dimension (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
416-0037	TS-5507	¥ 370	¥ 400	5.5 x 7	122	10	20
416-0045	TS-0607	¥ 370	¥ 400	6.0 x 7	122	10	20
416-0053	TS-0608	¥ 370	¥ 400	6.0 x 8	122	10	20
416-0061	TS-0708	¥ 370	¥ 400	7.0 x 8	122	10	20
416-0070	TS-0809	¥ 370	¥ 400	8.0 x 9	140	10	32
416-0088	TS-0810	¥ 389	¥ 420	8.0 x 10	140	10	32
416-0096	TS-1012	¥ 435	¥ 470	10.0 x 12	156	10	47
416-0100	TS-1013	¥ 435	¥ 470	10.0 x 13	172	10	62
416-0118	TS-1113	¥ 435	¥ 470	11.0 x 13	172	10	61
416-0126	TS-1214	¥ 435	¥ 470	12.0 x 14	180	10	72
416-0134	TS-1317	¥ 490	¥ 530	13.0 x 17	188	10	88
416-0142	TS-1417	¥ 490	¥ 530	14.0 x 17	188	10	90
416-0151	TS-1719	¥ 611	¥ 660	17.0 x 19	220	10	158
416-0169	TS-1921	¥ 694	¥ 750	19.0 x 21	234	10	192
416-0177	TS-1922	¥ 694	¥ 750	19.0 x 22	234	10	192
416-0185	TS-1924	¥ 694	¥ 750	19.0 x 24	234	10	200
416-0193	TS-2123	¥ 787	¥ 850	21.0 x 23	247	10	220
416-0207	TS-2224	¥ 787	¥ 850	22.0 x 24	247	10	234
416-0215	TS-2427	¥ 907	¥ 980	24.0 x 27	266	5	318
416-0223	TS-2430	¥ 1,138	¥ 1,230	24.0 x 30	285	5	377
416-0231	TS-2730	¥ 1,398	¥ 1,510	27.0 x 30	302	5	456
416-0240	TS-3032	¥ 1,398	¥ 1,510	30.0 x 32	302	5	481



TS-6SB (when opening)



(when in storage)

Set Accessories • Storage Pouch

Order Unit: 1 Set


Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
416-0258	TS-6SA	¥ 3,009	¥ 3,250	8 x 9, 10 x 12, 12 x 14, 14 x 17, 17 x 19, 21 x 23	6	1	799
416-0266	TS-6SB	¥ 2,851	¥ 3,080	5.5 x 7, 8 x 10, 11 x 13, 12 x 14, 17 x 19, 22 x 24	6	1	757
416-0274	TS-6SC	¥ 3,360	¥ 3,630	8 x 9, 10 x 12, 12 x 14, 14 x 17, 19 x 21, 24 x 27	6	1	931
416-0282	TS-6SD	¥ 3,055	¥ 3,300	8 x 9, 10 x 12, 12 x 14, 14 x 17, 19 x 21, 23 x 26	6	1	879
416-0291	TS-7S	¥ 3,157	¥ 3,410	5.5 x 7, 8 x 10, 10 x 12, 11 x 13, 12 x 14, 14 x 17, 17 x 19	7	1	670

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock 1,637 Items

Double-end Wrench

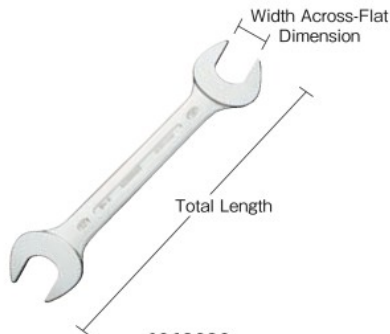

6063830

Features • The surface is satin finish, easy to fit in and hard to slip specifications.

• The handle shaft is a slim type.

Specs • Chrome plated finish

Materials • Chrome Vanadium Steel (Cr-V)

Origin • Germany

Order Unit: 1 Piece

GEDORE Werkzeugfabrik GmbH & Co. KG

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Width Across-Flat Dimension (mm)	Total Length (mm)	Thickness (mm)	SPQ (piece)	Weight (g)	Order Code	Item No.	Price (per piece)	MSRP (per piece)	Width Across-Flat Dimension (mm)	Total Length (mm)	Thickness (mm)	SPQ (piece)	Weight (g)
855-4037	6063830	¥ 517	—	6 x 7	122	3.5	10	22	855-4054	6066500	¥ 995	—	18 x 19	222	6.5	10	174
855-4038	6064050	¥ 660	—	7 x 8	140	3.8	10	34	855-4069	6069360	¥ 1,281	—	18 x 21	236	7.0	10	196
855-4039	6064210	¥ 532	—	8 x 9	140	3.8	10	35	855-4055	6066770	¥ 1,199	—	19 x 22	236	7.0	10	219
855-4040	6064480	¥ 648	—	8 x 10	140	4.0	10	36	855-4056	6066930	¥ 1,365	—	19 x 24	250	7.5	10	256
855-4041	6064720	¥ 605	—	10 x 11	157	4.5	10	50	855-4070	6069440	¥ 1,479	—	21 x 24	250	7.5	10	268
855-4042	6064990	¥ 810	—	10 x 13	172	5.0	10	65	855-4057	6067150	¥ 1,350	—	22 x 24	250	7.5	10	260
855-4043	6065100	¥ 822	—	11 x 13	172	5.0	10	68	855-4058	6067580	¥ 1,554	—	24 x 27	266	8.0	10	337
855-4044	6065370	¥ 728	—	12 x 13	172	5.0	10	69	855-4059	6067660	¥ 1,832	—	24 x 30	280	8.5	10	390
855-4045	6065450	¥ 818	—	12 x 14	172	5.0	10	76	855-4060	6067900	¥ 2,171	—	27 x 30	302	9.0	10	466
855-4046	6065530	¥ 818	—	13 x 14	178	5.0	10	81	855-4061	6068040	¥ 2,171	—	27 x 32	302	9.0	10	487
855-4047	6065610	¥ 885	—	13 x 15	188	5.5	10	98	855-4062	6068120	¥ 2,171	—	30 x 32	302	9.0	10	504
855-4068	6068980	¥ 922	—	13 x 16	190	5.5	10	98	855-4071	6069520	¥ 2,481	—	30 x 34	302	9.0	10	503
855-4048	6065880	¥ 782	—	14 x 15	188	5.5	10	95	855-4063	6068200	¥ 3,984	—	30 x 36	328	9.4	1	677
855-4049	6065960	¥ 900	—	13 x 17	205	6.0	10	122	855-4064	6068390	¥ 3,984	—	32 x 36	328	9.4	1	594
855-4050	6066180	¥ 900	—	14 x 17	205	6.0	10	119	855-4072	6069600	¥ 4,702	—	34 x 36	328	9.4	1	624
855-4051	6066260	¥ 843	—	16 x 17	205	6.0	10	128	855-4065	6068470	¥ 5,266	—	36 x 41	360	10.0	1	770
855-4052	6066340	¥ 1,011	—	16 x 18	205	6.0	10	129	855-4066	6068630	¥ 7,008	—	41 x 46	400	10.7	1	1104
855-4053	6066420	¥ 1,026	—	17 x 19	222	6.5	10	168	855-4067	6068710	¥ 9,771	—	46 x 50	450	11.6	1	1445

Contact us: 03-3433-9841 <http://www.orange-book.com/>