

# Ball-Point Hexagonal Wrenches

The number next to the logo mark indicates items in stock for each brand.

Screwdrivers - Hexagonal Wrenches

Grip Screwdrivers

Screwdrivers with Plastic Handle

Stubby Screwdrivers

Screwdrivers with Wood Handle

Precision Screwdrivers

Electric Detection Screwdrivers

Interchangeable Screwdrivers

Ratchet Screwdrivers

Offset Ratchet Screwdrivers

Socket Screwdrivers

Impact Drivers (Manual Type)

Hexagon Driver

Hex Lobe Screwdrivers

Special-Purpose Screwdrivers

Ball-Point Hexagonal Wrenches

Hexagonal Wrenches

Hex Lobe Wrenches



Stock 38,650 Items

## Ball-Point Hexagonal Wrench (long type)



- Features**
- Long type easy power application.
  - Surface treatment is black dye processing.
  - The hardness is HRC52 to 56.
- Materials**
- Chrome Vanadium Steel (Cr-V)
- Origin**
- Taiwan



TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side Dimension (mm)	Length Excl. Head (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
389-6528	TBRL-15	¥ 130	¥ 140	1.5	14	90	30	1.60
389-6536	TBRL-20	¥ 139	¥ 150	2.0	16	100	30	3.18
389-6544	TBRL-25	¥ 158	¥ 170	2.5	18	112	30	5.57
389-6552	TBRL-30	¥ 176	¥ 190	3.0	20	126	30	8.95
389-6561	TBRL-40	¥ 185	¥ 200	4.0	25	140	30	18.00
389-6579	TBRL-45	¥ 204	¥ 220	4.5	26	150	30	24.40
389-6587	TBRL-50	¥ 213	¥ 230	5.0	28	160	30	31.90
389-6595	TBRL-55	¥ 231	¥ 250	5.5	30	170	30	41.10
389-6609	TBRL-60	¥ 259	¥ 280	6.0	32	180	30	52.00
389-6617	TBRL-70	¥ 296	¥ 320	7.0	34	190	20	74.90
389-6625	TBRL-80	¥ 361	¥ 390	8.0	36	200	20	104.10
389-6633	TBRL-100	¥ 537	¥ 580	10.0	40	224	10	182.20
389-6641	TBRL-120	¥ 814	¥ 880	12.0	45	250	10	293.40
389-6650	TBRL-140	¥ 1,185	¥ 1,280	14.0	56	280	10	452.40

- Set** Features
- Since the holder rotates, it is easy to put in and out each size of hexagonal wrench.
- Accessories
- Holder

Order Unit: 1 Set


Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
366-8843	TBRL-9S	¥ 2,546	¥ 2,750	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10	9	6	422
366-8835	TBRL-12S	¥ 3,055	¥ 3,300	1.5, 2, 2.5, 3, 4, 4.5, 5, 5.5, 6, 7, 8, 10	12	6	610

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items

## Ball-Point Hexagonal Wrench (short type)

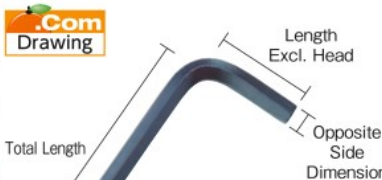

- Features**
- Since the holder rotates, it is easy to put in and out each size of hexagonal wrench.
  - Surface treatment is black dye processing.
  - The hardness is HRC50 to 58.
- Materials**
- Chrome Vanadium Steel (Cr-V)
- Origin**
- Taiwan

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side Dimension (mm)	Length Excl. Head (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
389-5831	TBRS-15	¥ 93	¥ 100	1.5	14	45	50	0.91
389-5840	TBRS-20	¥ 102	¥ 110	2.0	16	50	50	1.82
389-5858	TBRS-25	¥ 111	¥ 120	2.5	18	56	50	3.19
389-5866	TBRS-30	¥ 120	¥ 130	3.0	20	63	50	5.15
389-5874	TBRS-40	¥ 130	¥ 140	4.0	25	70	50	10.40
389-5882	TBRS-45	¥ 139	¥ 150	4.5	26	75	50	14.10
389-5891	TBRS-50	¥ 158	¥ 170	5.0	28	80	50	18.50
389-5904	TBRS-55	¥ 166	¥ 180	5.5	30	85	50	24.00
389-5912	TBRS-60	¥ 176	¥ 190	6.0	32	90	50	30.43
389-5921	TBRS-70	¥ 185	¥ 200	7.0	34	95	50	43.88
389-5939	TBRS-80	¥ 204	¥ 220	8.0	36	100	50	60.52
389-5947	TBRS-100	¥ 278	¥ 300	10.0	40	112	40	105.00
389-5955	TBRS-120	¥ 500	¥ 540	12.0	45	125	30	170.00
389-5963	TBRS-140	¥ 750	¥ 810	14.0	56	140	20	265.60
389-5971	TBRS-170	¥ 1,407	¥ 1,520	17.0	63	160	10	442.00
389-5980	TBRS-190	¥ 1,889	¥ 2,040	19.0	63	180	10	631.20

- Set** Accessories
- Holder

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
389-5998	TBRS-9S	¥ 1,620	¥ 1,750	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10	9	6	258
389-6005	TBRS-12S	¥ 1,972	¥ 2,130	1.5, 2, 2.5, 3, 4, 4.5, 5, 5.5, 6, 7, 8, 10	12	6	343

Contact us: 0120-509-849 <http://www.orange-book.com/>