

Ball-Point Hexagonal Wrenches (short below head/long below head)

Stock 1,057 Items

4-747

Prices displayed include 8% tax.



Stock 38,650 Items

Ball-Point Hexagonal Wrench (short neck type)



TBKS-80



TBKS-9S (set)

- Features**
- High torque, strong nickel chrome molybdenum steel is adopted.
 - The holder rotates, making it easy to put in and out wrenches of various sizes.
 - Matte chrome plating.
 - The hardness is HRC55 to 60.
- Materials**
- Nickel Chrome Molybdenum Steel
- Origin**
- Taiwan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side Dimension (mm)	Length Excl. Head (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
389-6811	TBKS-15	¥204	¥220	1.5	6	45	12	1
389-6820	TBKS-20	¥259	¥280	2.0	7	50	12	2
389-6838	TBKS-25	¥278	¥300	2.5	8	56	12	3
389-6846	TBKS-30	¥306	¥330	3.0	9	63	12	4
389-6854	TBKS-40	¥334	¥360	4.0	11	70	12	9
389-6862	TBKS-50	¥370	¥400	5.0	12	80	12	15
389-6871	TBKS-60	¥463	¥500	6.0	14	90	12	25
389-6889	TBKS-80	¥565	¥610	8.0	16	100	12	49
389-6897	TBKS-100	¥806	¥870	10.0	19	112	12	87

Set Accessories • Holder

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
389-6901	TBKS-9S	¥3,462	¥3,740	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10	9	6	221

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items

Ball-Point Hexagonal Wrench (short neck, long type)



TBKL-80



TBKL-9S (set)

- Features**
- High torque, strong nickel chrome molybdenum steel is adopted.
 - The holder rotates, making it easy to put in and out wrenches of various sizes.
 - Matte chrome plating.
 - The hardness is HRC55 to 60.
- Materials**
- Nickel Chrome Molybdenum Steel
- Origin**
- Taiwan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side Dimension (mm)	Length Excl. Head (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
389-6919	TBKL-15	¥306	¥330	1.5	6	90	6	1.5
389-6927	TBKL-20	¥334	¥360	2.0	7	100	6	3.0
389-6935	TBKL-25	¥370	¥400	2.5	8	112	6	5.0
389-6943	TBKL-30	¥426	¥460	3.0	9	126	6	8.0
389-6951	TBKL-40	¥500	¥540	4.0	11	140	6	16.0
389-6960	TBKL-50	¥602	¥650	5.0	12	160	6	28.0
389-6978	TBKL-60	¥694	¥750	6.0	14	180	6	46.0
389-6986	TBKL-80	¥833	¥900	8.0	16	200	6	93.0
389-6994	TBKL-100	¥1,074	¥1,160	10.0	19	224	6	164.0

Set Accessories • Holder

Order Unit: 1 Set


Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
389-7001	TBKL-9S	¥4,378	¥4,730	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10	9	6	395

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items

Ball-Point Hexagonal Wrench (long neck/long type)

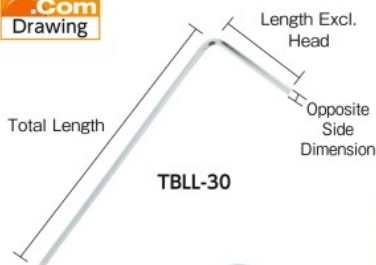

TBLL-30



TBLL-9S (set)

- Features**
- Ideal for tightening in deep locations.
 - High torque, strong nickel chrome molybdenum steel is adopted.
 - The holder rotates, making it easy to put in and out wrenches of various sizes.
- Materials**
- Nickel Chrome Molybdenum Steel
- Origin**
- Taiwan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side Dimension (mm)	Length Excl. Head (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
415-8946	TBLL-15	¥370	¥400	1.5	28	90	12	2.0
415-8954	TBLL-20	¥399	¥430	2.0	32	100	12	4.0
415-8962	TBLL-25	¥435	¥470	2.5	36	112	12	7.0
415-8971	TBLL-30	¥509	¥550	3.0	40	126	12	10.0
415-8989	TBLL-40	¥593	¥640	4.0	50	140	12	21.0
415-8997	TBLL-50	¥713	¥770	5.0	56	160	12	36.0
415-9004	TBLL-60	¥814	¥880	6.0	64	180	6	58.5
415-9012	TBLL-80	¥982	¥1,060	8.0	72	200	6	116.5
415-9021	TBLL-100	¥1,259	¥1,360	10.0	80	224	6	203.0

Set Accessories • Holder

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
415-9039	TBLL-9S	¥5,156	¥5,570	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10	9	6	484

Contact us: 0120-509-849 <http://www.orange-book.com/>