

Ball-Point Hexagonal Wrenches (T-shaped)

Stock 1,057 Items

4-763

Prices displayed include 8% tax.



Stock 38,650 Items

T-Handle Ball-Point Hexagonal Wrench



- Features
- Suitable for machine maintenance and maintenance repair.
 - Easy to hold T-handle specification.
 - Able to tilt the Ball-point portion up to about 25° in one corner.
 - Surface treatment is black dye processing.
 - The hardness is HRC50 to 57.
- Origin • Taiwan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side Dimension (mm)	Total Length (mm)	Total Width (mm)	SPQ (piece)	Weight (g)
342-9644	TSBR-20	¥379	¥410	2.0	150	86	20	23
342-9652	TSBR-25	¥399	¥430	2.5	150	86	20	26
342-9661	TSBR-30	¥426	¥460	3.0	150	86	20	29
342-9679	TSBR-40	¥482	¥520	4.0	190	105	20	52
342-9687	TSBR-50	¥537	¥580	5.0	190	105	20	64
342-9695	TSBR-60	¥611	¥660	6.0	230	130	20	110
342-9709	TSBR-80	¥787	¥850	8.0	230	130	20	147
342-9717	TSBR-100	¥852	¥920	10.0	230	130	20	206

Set Accessories • Stand

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
342-9725	TSBR-8S	¥5,045	¥5,450	2, 2.5, 3, 4, 5, 6, 8, 10	8	12	947

Hexagonal Wrench Set Stand (TSRR-8S, TSBR-8S only)

- Features
- Can be placed as a stand, or it can be hung on a hook hole.

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Applicable	SPQ (piece)	Weight (g)
389-7010	TSRS-8	¥814	¥880	TSRR-8S, TSBR-8S	12	281

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock 2,937 Items

Grip Ball-Point Hexagonal Wrench



- Features
- T type resin grip.
 - The grip part is subjected to anti-slip treatment.
 - For a size of 5 to 10mm, hexagonal bar of the same size is arranged at the end of the grip.
- Origin • Japan

Order Unit: 1 Piece

TONE CO. LTD.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side Dimension (mm)	Total Length (mm)	Total Width (mm)	SPQ (piece)	Weight (g)
453-8145	GBHW-2.5	¥486	¥610	2.5	128	64	6	20
369-8271	GBHW-03	¥532	¥660	3.0	134	64	6	25
369-8289	GBHW-04	¥540	¥675	4.0	140	64	6	35
369-8297	GBHW-05	¥779	¥975	5.0	158	91	6	80
369-8301	GBHW-06	¥833	¥1,035	6.0	172	91	6	110
369-8319	GBHW-08	¥957	¥1,195	8.0	191	91	6	150
369-8327	GBHW-10	¥1,188	¥1,485	10.0	210	91	6	200

Set Accessories • Stand

Order Unit: 1 Set


Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (kg/set)
369-8343	GBHW700	¥6,696	¥8,350	2.5, 3, 4, 5, 6, 8, 10	7	1	0.91

Contact us: 0721-56-1850 <http://www.tonetool.co.jp/>



Stock 252 Items

T-Shaped Hexagonal Spanner (long type)

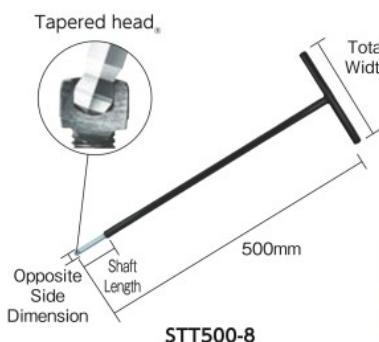

- Features
- The total length below the head is 500mm and is long, so it demonstrates its power when tightening screws in deep places.
 - 10 to 20% torsional strength is higher than conventional ball end, and it is particularly effective for use with inclination (0 to 20°).
- Origin • Japan

Order Unit: 1 Piece

EIGHT TOOL Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side Dimension (mm)	Shaft Length (mm)	Total Length (mm)	Total Width (mm)	SPQ (piece)	Weight (g)
360-5256	STT500-3	¥2,901	¥3,760	3	25	500	80	10	222.5
360-5264	STT500-4	¥2,985	¥3,870	4	35	500	100	10	228.0
360-5272	STT500-5	¥3,140	¥4,070	5	50	500	120	10	362.0
360-5281	STT500-6	¥4,011	¥5,200	6	50	500	160	10	551.0
360-5299	STT500-8	¥5,107	¥6,620	8	60	500	180	10	771.5

Contact us: 06-6793-9025 <http://www.eight-tool.co.jp/>