

The number next to the logo mark indicates items in stock for each brand.

TRUSCO **Stock**
38,650
Items

Pliers




Tip Shape



TP-200

Features

- The surface has fine finish and gloss. Moreover, rust resistance process has been applied and is strong against rust.
- Has a 2 stage adjustment type with mouth opening.
- Chrome Vanadium Steel
- China

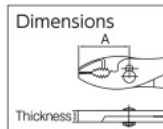Materials
Origin

 
Dimensions



Tip Shape



P150



Dimensions

Thickness

Order Unit: 1 Piece (Price revision date: Jan, 2015) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Thickness (mm)	A (mm)	Cutting Performance (mm)	SPQ (piece)	Weight (g)
253-4843	TP-150	¥ 842	¥ 910	160	9	40	φ2.2	5	190
253-4851	TP-200	¥1,009	¥1,090	205	10	44	φ2.2	5	270
253-4860	TP-250	¥1,166	¥1,260	245	12	58	φ3.2	5	425

Contact us:0120-509-849 <http://www.orange-book.com/>

LOBTEX **Stock**
1,809
Items

Pliers

Features

- Standard pliers excellent in corrosion resistance and durability.
- Hold firmly without backlash.
- Special Steel
- Japan

Materials
Origin

Order Unit: 1 Piece

(Price revision date: Jan, 2016) LOBTEX Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Thickness (mm)	A (mm)	Cutting Performance (mm)	SPQ (piece)	Weight (g)
124-9461	P150	¥1,290	¥1,360	165	9	41.5	φ2.0	6	160
124-9479	P200	¥1,479	¥1,560	203	11	46.0	φ2.6	6	250
124-9487	P250	¥2,160	¥2,290	248	12	58.0	φ3.2	6	360


Contact us:072-980-1111 <http://www.lobtex.co.jp/>

LOBTEX **Stock**
1,809
Items

Pliers



Tip Shape

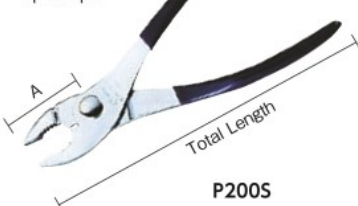

P200S

Features

- Adopting a special spring mechanism and a soft grip, they relieve fatigue of a hand due to long hours of work.

Materials
Origin

- Special Steel
- Japan



Tip Shape



CP-150SG

Features

- The opening of the jaws can be set at two steps according to the size of the object being gripped.
- With a soft grip to easily fit to your hands.

Materials
Origin

- Structural Steel
- Japan

Order Unit: 1 Piece (Price revision date: Jan, 2016) LOBTEX Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Thickness (mm)	A (mm)	Cutting Performance (mm)	SPQ (piece)	Weight (g)
372-5693	P150S	¥1,383	¥1,460	168	9	41.5	2.0	6	160
372-5707	P200S	¥1,614	¥1,710	206	11	46.0	2.6	6	250

Contact us:072-980-1111 <http://www.lobtex.co.jp/>

Order Unit: 1 Piece

TONE CO. LTD.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Thickness (mm)	A (mm)	Cutting Performance (mm)	SPQ (piece)	Weight (g)
407-8934	CP-150SG	¥1,389	¥1,730	167	9.4	42	φ3.0	6	175
407-8942	CP-200SG	¥1,581	¥1,970	210	10.9	45	φ4.0	6	265

Contact us:0721-56-1850 <http://www.tonetool.co.jp/>

LOBTEX **Stock**
1,809
Items

"Skeleton Pliers"



Tip Shape



SP200G (green)

Features

- Standard combination pliers with skeleton grip.
- A convenient 6 color grip for tool management for each workplace. (green, red, blue, yellow, violet, smoke)

Materials
Origin

- Special Steel
- Japan



SP200Y (yellow)



SP200V (violet)



SP200S (smoke)



Dimensions

11mm



SP200R (red)

SP200B (blue)

Order Unit: 1 Piece

(Price revision date: Jan, 2016) LOBTEX Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Grip Color	Total Length (mm)	Thickness (mm)	A (mm)	Cutting Performance (mm)	SPQ (piece)	Weight (g)
342-6327	SP200G	¥1,607	¥1,700	Green	205	11	46	2.6	6	260
342-6319	SP200R	¥1,607	¥1,700	Red	205	11	46	2.6	6	260
342-6335	SP200B	¥1,607	¥1,700	Blue	205	11	46	2.6	6	260
342-6271	SP200Y	¥1,607	¥1,700	Yellow	205	11	46	2.6	6	260
342-6262	SP200V	¥1,607	¥1,700	Violet	205	11	46	2.6	6	260
342-6254	SP200S	¥1,607	¥1,700	Smoke	205	11	46	2.6	6	260

Contact us:072-980-1111 <http://www.lobtex.co.jp/>