


Prices displayed include 8% tax.


**TRUSCO** Stock **38,650** Items

## Long Nose Pliers

**Com** Drawing



Tip Shape



TLP-160

165mm

Features


- The tip is long and thin, it is convenient for processing small articles.
- The surface has fine finish and gloss.
- Since rust prevention processing has been applied, it is strong against rust.
- Serrated tip
- Chrome Vanadium Steel
- China

Specs

Materials

Origin

Dimensions

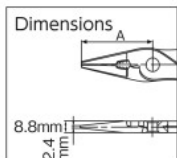

8.8mm

Order Unit: 1 Piece (Price revision date: Jan, 2015) TRUSCO NAKAYAMA CORPORATION


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Thickness (mm)	A (mm)	Cutting Performance (mm)	SPQ (piece)	Weight (g)
253-4916	TLP-160	¥870	¥940	165	8.8	55	Φ2.2	5	180

Contact us:0120-509-849 <http://www.orange-book.com/>


**TRUSCO** Stock **38,650** Items

## Thin Nose Pliers

 **Com** Drawing



Tip Shape



TTP-175

180mm

Features


- The tip is thin in 4.6mm. Can be used conveniently even in narrow places.
- Has a 2 stage adjustment with mouth opening.
- Serrated tip
- Chrome Vanadium Steel
- China

Specs

Materials

Origin


Detail Drawing

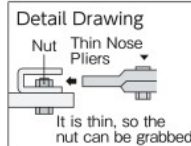

Nut Thin Nose Pliers

It is thin, so the nut can be grabbed.

Dimensions

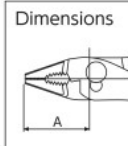

Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Thickness (mm)	A (mm)	Cutting Performance (mm)	SPQ (piece)	Weight (g)
252-6476	TTP-175	¥833	¥900	180	4.6	49.5	Φ2.2	6	210

Contact us:0120-509-849 <http://www.orange-book.com/>


**LOBTEX** Stock **1,809** Items

## Thin Nose Pliers

**Com** Drawing



Tip Shape

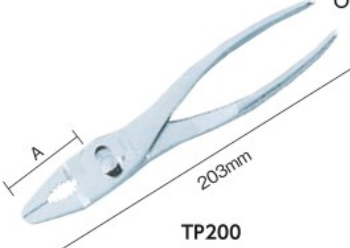

TP200

203mm

Features

- With a thin head, it can be used in narrow places or intended for light work.
- Optimum for car maintenance.
- Serrated tip
- Special Steel
- Japan

Specs

Materials

Origin

Order Unit: 1 Piece LOBTEX Co.Ltd.


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Thickness (mm)	A (mm)	Cutting Performance (mm)	SPQ (piece)	Weight (g)
372-6495	TP200	¥1,985	¥2,100	203	5.5	55.8	Φ2.6	6	250

Contact us:072-980-1111 <http://www.lobtex.co.jp/>


**TOP** Stock **1,160** Items

## Nose Pliers

**Com** Drawing



Tip Shape



BN-200 (thin bent nose)

Total Length



Tip Shape



SN-200 (thin straight nose)

Features

- With a thin tip, it is optimum for narrow places.
- Can be used for various purposes such as gripping and rotating objects and cutting wire.
- With angle and easy to use.
- Serrated tip
- Carbon Steel
- Japan

Specs

Materials

Origin

Order Unit: 1 Piece (Price revision date: Apr, 2016) TOP KOGYO Co.Ltd

 
Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Thickness (mm)	A (mm)	Cutting Performance (mm)	SPQ (piece)	Weight (g)
369-0024	BN-200	¥1,890	¥2,450	201	5.5	55	Φ2.6	6	240
369-2809	SN-200	¥1,736	¥2,250	203	5.5	55	Φ2.6	6	240

Contact us:0256-33-1681 <http://www.toptools.co.jp/>


**KNIPEX** Stock **942** Items

## Flat Nose Pliers

**Com** Drawing




Tip Shape




2001-160 (handle: soft plastic coating)

Total Length



Tip Shape



2002-160SB (handle: comfort)

Features

- With excellent wear resistance, optimum for heavy-duty use.
- The tip is flat, short and wide.
- Serrated tip
- Oil quenched tempered chrome vanadium electric steel
- Germany

Specs

Materials

Origin

### Handle: Soft plastic coating

Order Unit: 1 Piece KNIPEX-Werk C. Gustav Putsch KG

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Thickness (mm)	SPQ (piece)	Weight (g)
786-7417	2001-125	¥2,658	¥2,650	125	8.0	6	75
786-7425	2001-140	¥2,658	¥2,650	140	9.5	6	107
786-7433	2001-160	¥2,758	¥2,750	160	9.5	6	144
786-7441	2001-180	¥3,561	¥3,550	180	10.0	6	188

### Handle: Comfort

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Thickness (mm)	SPQ (piece)	Weight (g)
786-7450	2002-140	¥3,160	¥3,150	140	9.5	6	137
786-7468	2002-160SB	¥3,261	¥3,250	160	9.5	6	172

URL <http://www.knipex.com/index.php?id=113&l=17>