



Stock
38,650
 Items

JIS Cutting Plier

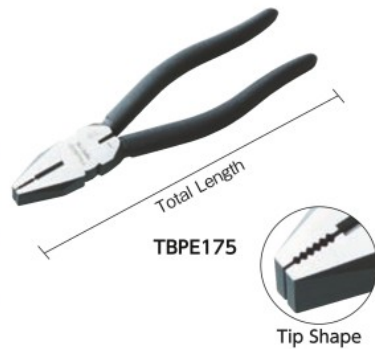

- Features
- Standard type Pliers.
 - Since it has special steel by our own development, it is excellent in sharpness and durability, and it can be used for a wide range of applications from pro to general household.
- Origin
- Vietnam



Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Cutting Performance (mm)			Fall prevention string attaching hole	Total Length (mm)	SPQ (piece)	Weight (g)
				Iron Wire	Copper Wire	VA Wire (VVF)				
365-4974	TBPE150	¥2,064	¥2,230	Φ2.2	Φ3.0	1.6 x 3 Core	None	160	5	180
365-4982	TBPE175	¥2,157	¥2,330	Φ3.0	Φ3.5	2.0 x 3 Core	None	186	5	260
384-1979	TBPE200	¥2,343	¥2,530	Φ3.4	Φ4.0	2.0 x 3 Core	None	210	5	325


TRUSCO NAKAYAMA CORPORATION

Contact us: 0120-509-849 <http://www.orange-book.com/>
Stock
222
 Items

JIS Cutting Plier



- Features
- Using the finest special steel, it is a standard pliers with outstanding durability.
 - Knurling processing has been applied, you can also turn nuts etc.
- Specs
- Serrated tip
- Origin
- Japan

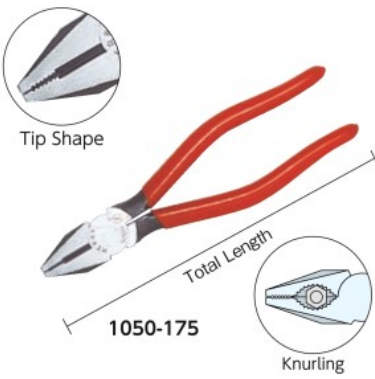

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Cutting Performance (mm)			Fall prevention string attaching hole	Total Length (mm)	SPQ (piece)	Weight (g)
				Iron Wire	Copper Wire	VA Wire (VVF)				
104-1606	1050-150	¥2,916	¥3,780	Φ2.0	Φ3.0	1.6 x 3 Core	None	150	6	200
104-1614	1050-175	¥3,178	¥4,120	Φ2.6	Φ3.5	2.0 x 3 Core	None	175	6	275
104-1622	1050-200	¥3,564	¥4,620	Φ3.2	Φ4.0	2.0 x 3 Core	None	200	6	375


(Price revision date: Sep, 2015) MUROMOTO TEKKO Co.Ltd

URL <http://www.muromoto.co.jp/>
Stock
222
 Items

JIS Cutting Plier



- Features
- Appropriate slip prevention is applied to the grip part.
 - Knurling processing has been applied, you can also turn nuts etc.
- Origin
- Japan

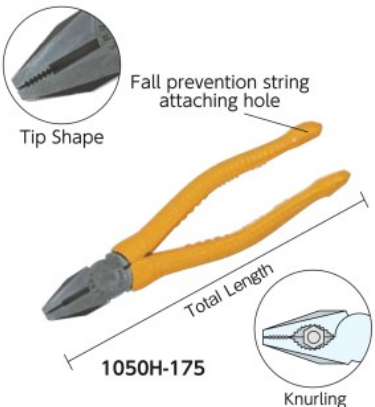

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Cutting Performance (mm)			Fall prevention string attaching hole	Total Length (mm)	SPQ (piece)	Weight (g)
				Iron Wire	Copper Wire	VA Wire (VVF)				
104-1193	1050H-150	¥3,024	¥3,920	Φ2.0	Φ3.0	1.6 x 3 Core	None	150	6	210
104-1207	1050H-175	¥3,286	¥4,260	Φ2.6	Φ3.5	2.0 x 3 Core	Yes	175	6	285
104-1215	1050H-200	¥3,687	¥4,780	Φ3.2	Φ4.0	2.0 x 3 Core	Yes	200	6	385


(Price revision date: Sep, 2015) MUROMOTO TEKKO Co.Ltd

URL <http://www.muromoto.co.jp/>
Stock
222
 Items

High Leverage Cutting Pliers



- Features
- Since the fulcrum is shorter from the tip than the ordinary pliers, it has excellent cutting performance. (eccentricity lever principle was adopted)
 - Appropriate slip prevention is applied to the grip part.
 - Knurling processing has been applied, you can also turn nuts etc.
- Origin
- Japan

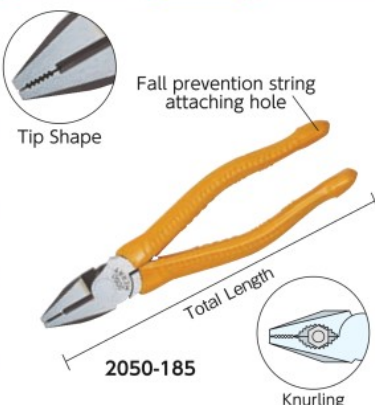

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Cutting Performance (mm)			Fall prevention string attaching hole	Total Length (mm)	SPQ (piece)	Weight (g)
				Iron Wire	Copper Wire	VA Wire (VVF)				
104-1274	2050-185	¥3,687	¥4,780	Φ3.2	Φ4.0	2.0 x 3 Core	Yes	185	6	290
104-1282	2050-225	¥3,888	¥5,040	Φ3.6	Φ4.5	2.6 x 3 Core	Yes	225	6	370

(Price revision date: Sep, 2015) MUROMOTO TEKKO Co.Ltd

URL <http://www.muromoto.co.jp/>