


For Repair Mechanical Springs, see p. 4-1002

The number next to the logo mark indicates items in stock for each brand.

TRUSCO **Stock 38,650 Items** **Needle-Nose Pliers** **RoHS**

Com Drawing

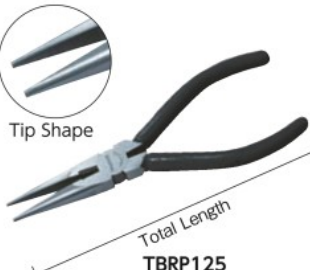

Tip Shape

Total Length

TBRP125

Tip Shape

2.5 mm

3mm

Features

- The tip is tough, it does not break and bend, and it is excellent in sharpness.
- With mechanical spring
- Serrated tip
- JIS standard product (150mm only)


Specs

- Special Steel
- Vietnam

Materials

Origin

TRUSCO **Stock 38,650 Items** **Long Needle-Nose Pliers** **RoHS**



Tip Shape

172mm

TBLRP170

Tip Shape

2 mm

2.5mm

Features

- Improved needle-nose pliers.
- Having a long tip, it is optimum for work of deep parts.
- With plier function.
- Serrated tip
- Special Steel
- Japan

Specs

Materials

Origin

Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Cutting Performance (mm)		Total Length (mm)	SPQ (piece)	Weight (g)
				Iron Wire	Copper Wire			
437-8172	TBRP125	¥1,907	¥2,060	φ1.5	φ2.6	142	5	95
365-5016	TBRP150	¥2,055	¥2,220	φ1.5	φ2.6	160	5	120


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Cutting Performance (mm)		Total Length (mm)	SPQ (piece)	Weight (g)
				Iron Wire	Copper Wire			
437-8181	TBLRP170	¥2,240	¥2,420	φ1.5	φ2.6	172	5	110

Contact us:0120-509-849 <http://www.orange-book.com/>

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items** **All Purpose Needle-Nose Pliers** **RoHS**

Com Drawing



Tip Shape

160mm

TBUPR150

Tip Shape

2.5 mm

3mm

Features

- The tip is tough, it does not break and bend, and it is excellent in sharpness.
- A versatile tool that can be used widely, such as interrupting cutting of cords, simple crimping, peeling of wire rod, pinching and turning machine screw and nuts, turning, with keeping the function of conventional needle-nose pliers.

Specs


- With mechanical spring
- Serrated tip
- Special Steel
- Vietnam

Materials

Origin

FUJIYA **Stock 283 Items** **Needle-Nose Pliers** **RoHS**

QUALITY FIRST

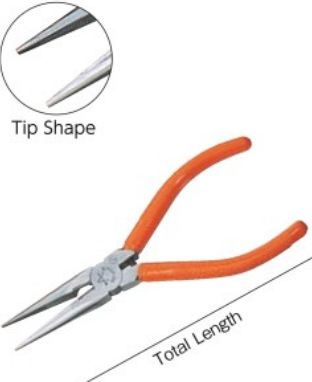

Tip Shape

Total Length

350S-150

Tip Shape

Features

- The most standard radio pliers, can be used for a wide range of applications.
- The tip is tough with excellent durability, optimal for folding and bending works.
- The replacement springs are FNS-1 (5 pieces) 125mm and FNS-17 (5 pieces) 150mm.
- With mechanical spring
- Serrated tip
- Japan

Specs

Origin

SPQ: 6 Pieces

Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece (Price revision date: Aug, 2015) FUJIYA Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Cutting Performance (mm)		Total Length (mm)	SPQ (piece)	Weight (g)
				Iron Wire	Copper Wire			
365-5032	TBUPR150	¥2,157	¥2,330	φ1.5	φ2.6	160	5	120


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Cutting Performance (mm)		Total Length (mm)	Tip Shape (mm) E x F	Weight (g)
				Iron Wire	Copper Wire			
117-8709	350S-125	¥2,731	¥3,540	φ1.5	φ2.6	142	2.5 x 2.0	95
117-8717	350S-150	¥2,808	¥3,640	φ1.5	φ2.6	160	3.0 x 2.5	120

Contact us:0120-509-849 <http://www.orange-book.com/>

Contact us:0120-248-440 <http://www.fujiya-kk.com/>

FUJIYA **Stock 283 Items** **All Purpose Needle-Nose Pliers** **RoHS**

QUALITY FIRST

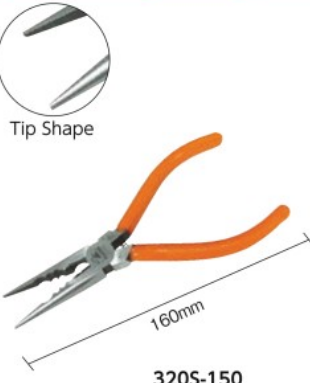

Tip Shape

160mm

320S-150

Tip Shape

2.5 mm

3mm

Features

- An universal very convenient tool that can be used widely, such as interrupting cutting of cords, simple crimping, peeling of wire, gripping machine screws and nuts without losing the function of existing radio pliers.
- Replacement spring FNS-17 (5 pieces).

Specs


- With mechanical spring
- Serrated tip

Origin

Japan

FUJIYA **Stock 283 Items** **Needle-Nose Pliers** **RoHS**

QUALITY FIRST



Tip Shape

Total Length

350-150

Tip Shape

Features

- The most standard radio pliers, can be used for a wide range of applications.
- The tip is tough with excellent durability, optimal for folding and bending works.
- Serrated tip
- Japan

Specs

Origin

SPQ: 6 Pieces

Order Unit: 1 Piece (Price revision date: Aug, 2015) FUJIYA Co.Ltd.

Order Unit: 1 Piece (Price revision date: Aug, 2015) FUJIYA Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Cutting Performance (mm)		Total Length (mm)	SPQ (piece)	Weight (g)
				Iron Wire	Copper Wire			
375-5436	320S-150	¥2,839	¥3,680	φ1.5	φ2.6	160	6	120

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Cutting Performance (mm)		Total Length (mm)	Tip Shape (mm) E x F	Weight (g)
				Iron Wire	Copper Wire			
117-8679	350-125	¥2,499	¥3,240	φ1.5	φ2.6	142	2.5 x 2.0	95
117-8687	350-150	¥2,607	¥3,380	φ1.5	φ2.6	160	3.0 x 2.5	120
117-8695	350-200	¥2,993	¥3,880	φ2.0	φ3.0	210	3.5 x 2.5	230

Contact us:0120-248-440 <http://www.fujiya-kk.com/>

Contact us:0120-248-440 <http://www.fujiya-kk.com/>