 


Double Ended Screwdriver Bits

For Impact, Electric Screwdriver, see p. 5-77 to 119, 124 to 156. For Air Screwdriver, see p. 5-459 to 467



Stock
38,650
Items

Screwdriver Bit




TB14-1-65G



TB14-2-110E



TB14-3-110E

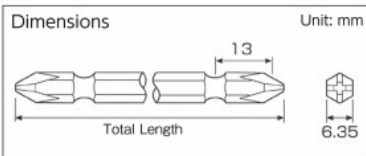TBM14-1-65H
(blade edge: with magnet)TBM14-1-110H
(blade edge: with magnet)

Features •We are using original special alloy steel and demonstrate excellent durability.

•Based on JIS standards and JICIS standards, manufacturing with strict dimensional precision, mating with screw is outstanding.

Specs •Shank Diameter: 6.35mm

Origin •Japan

Order Unit: 10 Pieces

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Q'ty Per Pack (piece)	Blade Edge	Total Length (mm)	Hardness	Weight (g)
437-3359	TB14-1-65G	¥106	¥130	10	⊕1	65	G	14
437-3367	TB14-1-65H	¥106	¥130	10	⊕1	65	H	14
437-3375	TB14-1-110G	¥146	¥180	10	⊕1	110	G	25
437-3383	TB14-1-110H	¥146	¥180	10	⊕1	110	H	25
437-3391	TB14-2-45E	¥106	¥130	10	⊕2	45	E	9
437-3405	TB14-2-45G	¥106	¥130	10	⊕2	45	G	9
437-3413	TB14-2-45H	¥106	¥130	10	⊕2	45	H	9
437-3421	TB14-2-65E	¥106	¥130	10	⊕2	65	E	14
437-3430	TB14-2-65G	¥106	¥130	10	⊕2	65	G	14
437-3448	TB14-2-65H	¥106	¥130	10	⊕2	65	H	14
478-9351	TB14-2-65X	¥122	¥150	10	⊕2	65	X	14
437-3456	TB14-2-110E	¥146	¥180	10	⊕2	110	E	25
437-3464	TB14-2-110G	¥146	¥180	10	⊕2	110	G	25
437-3472	TB14-2-110H	¥146	¥180	10	⊕2	110	H	25
478-9334	TB14-2-110X	¥162	¥200	10	⊕2	110	X	25
437-3481	TB14-2-150E	¥194	¥240	10	⊕2	150	E	36
437-3499	TB14-2-150G	¥194	¥240	10	⊕2	150	G	36
437-3502	TB14-2-150H	¥194	¥240	10	⊕2	150	H	36
478-9342	TB14-2-150X	¥219	¥270	10	⊕2	150	X	36
437-3511	TB14-2-200E	¥259	¥320	10	⊕2	200	E	49
437-3529	TB14-2-200G	¥259	¥320	10	⊕2	200	G	49
437-3537	TB14-2-200H	¥259	¥320	10	⊕2	200	H	49
437-3545	TB14-3-65E	¥106	¥130	10	⊕3	65	E	14
437-3553	TB14-3-65G	¥106	¥130	10	⊕3	65	G	14
437-3561	TB14-3-65H	¥106	¥130	10	⊕3	65	H	14
437-3570	TB14-3-110E	¥146	¥180	10	⊕3	110	E	25
437-3588	TB14-3-110G	¥146	¥180	10	⊕3	110	G	25
437-3596	TB14-3-110H	¥146	¥180	10	⊕3	110	H	25

Blade Edge: With magnet

Order Unit: 10 Pieces

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Q'ty Per Pack (piece)	Blade Edge	Total Length (mm)	Hardness	Weight (g)
437-3600	TBM14-1-65H	¥106	¥130	10	⊕1	65	H	14.0
437-3618	TBM14-1-110H	¥146	¥180	10	⊕1	110	H	25.0
437-3626	TBM14-2-45G	¥106	¥130	10	⊕2	45	G	9.0
437-3634	TBM14-2-45H	¥106	¥130	10	⊕2	45	H	9.0
437-3642	TBM14-2-65G	¥106	¥130	10	⊕2	65	G	14.0
437-3651	TBM14-2-65H	¥106	¥130	10	⊕2	65	H	14.0
437-3669	TBM14-2-110G	¥146	¥180	10	⊕2	110	G	25.0
437-3677	TBM14-2-110H	¥146	¥180	10	⊕2	110	H	25.0
437-3685	TBM14-2-150G	¥194	¥240	10	⊕2	150	G	36.0
437-3693	TBM14-2-150H	¥194	¥240	10	⊕2	150	H	36.0
856-3511	TBM16-56-65H	¥154	¥190	10	⊕5/⊕6	65	H	10.5
856-3512	TBM16-56-110H	¥203	¥250	10	⊕5/⊕6	110	H	27.0

Contact us: 0120-509-849 <http://www.orange-book.com/>



 
Stock
38,650
Items

Bit for Gripping Screws (with magnet)

RoHS



TKB-2Series



Features •Double protrusions formed on the surface to be mated with screws strikes the screw.


•We are using original special alloy steel and demonstrate excellent durability.

•Electroless nickel finish whose surface is hard and uniform and strong against rust.

Specs •Shank Diameter: 6.35mm

Origin •Blade Edge: With magnet

•Japan

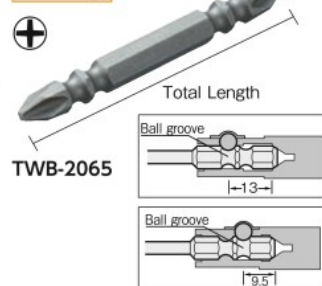

TWB-2065

Features •Shaft part is as thin as 4.5mm, it is optimum for screw tightening of thin hole, terminal block, recessed part.

•We use original special alloy steel and boast excellent accuracy and durability.

•W groove type which can be used for both 13mm and 9.5mm.

Specs •Shank Diameter: 6.35mm

Origin •Blade Edge: With magnet

•Japan

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Blade Edge	Total Length (mm)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
772-8255	TKB-2-65	¥407	¥440	⊕2	65	2	10	14
768-6978	TKB-2-110	¥518	¥560	⊕2	110	2	10	25
768-6986	TKB-2-150	¥713	¥770	⊕2	150	2	10	36

Contact us: 0120-509-849 <http://www.orange-book.com/>

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Blade Edge	Total Length (mm)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
286-8768	TWB-2065	¥1,065	¥1,150	⊕2	65	10	10	145
286-8776	TWB-2110	¥1,462	¥1,580	⊕2	110	10	10	255
286-8784	TWB-2150	¥1,851	¥2,000	⊕2	150	10	10	365

Contact us: 0120-509-849 <http://www.orange-book.com/>