

# Single Ended Screwdriver Bits (hexagon type)

For Impact, Electric Screwdriver, see p. 5-77 to 119, 124 to 156. For Air Screwdriver, see p. 5-459 to 467

Double End Drill Bit

Single End Drill Bit

Torsion Bits

Bits for Electric Screwdriver

Bits for Special-Purpose


Attachments for Bits

TRUSCO Stock 38,650 Items

## Hexagon Bit (with magnet)



- Features • Optimum for screw tightening of hexagon socket screw (cap screw and set screw etc.).  
 Specs • Shank Diameter: 6.35mm  
 • Blade Edge: With magnet  
 Origin • Japan

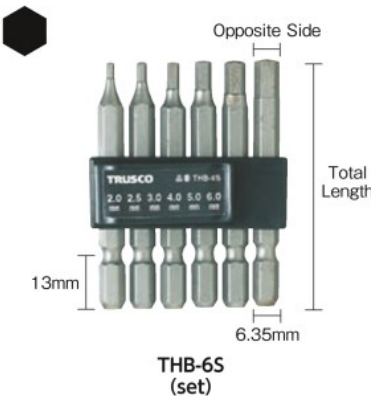

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side (mm)	Total Length (mm)	Hardness	SPQ (piece)	Weight (g)
765-2275	THBI-20	¥245	¥265	2.0	65	H	10	20
765-2283	THBI-25	¥245	¥265	2.5	65	H	10	20
765-2291	THBI-30	¥245	¥265	3.0	65	H	10	20
765-2305	THBI-40	¥245	¥265	4.0	65	H	10	20
765-2313	THBI-50	¥245	¥265	5.0	65	H	10	21
765-2321	THBI-60	¥245	¥265	6.0	65	H	10	22
765-2330	THBI-80	¥296	¥320	8.0	65	H	10	30
765-2267	THBI-100	¥379	¥410	10.0	65	H	10	35

Set Set Contents • Hexagon bit 2.0/2.5/3.0/4.0/5.0/6.0 1 piece each/Bit-holder

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Total Length (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
330-4019	THB-6S	¥1,296	¥1,400	65	6	6	146

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

## Long Hexagon Bit (with magnet)



- Features • Optimum for screw tightening of hexagon socket screw (cap screw and set screw etc.).  
 Specs • Shank Diameter: 6.35mm  
 • Blade Edge: With magnet  
 Origin • Japan



Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side (mm)	Total Length (mm)	Hardness	SPQ (piece)	Weight (g)
765-2348	THBL-20	¥518	¥560	2.0	150	H	10	34
765-2356	THBL-25	¥518	¥560	2.5	150	H	10	34
765-2364	THBL-30	¥518	¥560	3.0	150	H	10	35
765-2372	THBL-40	¥518	¥560	4.0	150	H	10	36
765-2381	THBL-50	¥518	¥560	5.0	150	H	10	39
765-2399	THBL-60	¥518	¥560	6.0	150	H	10	42

Set Set Contents • 2.0, 2.5, 3.0, 4.0, 5.0, 6.0, each 1 pieces, bit holder

Order Unit: 1 Set


Order Code	Item No.	Price (per set)	MSRP (per set)	Total Length (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
352-3748	THBL-6S	¥2,407	¥2,600	150	6	10	232

Contact us:0120-509-849 <http://www.orange-book.com/>

VESEL Stock 1,489 Items

## Hex Bit

- Features • Original special alloy steel is used.  
 Specs • Shank Diameter: 6.35mm  
 Origin • Japan

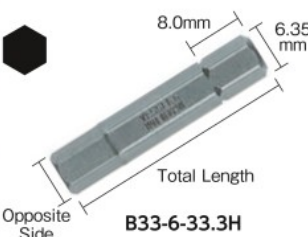

Order Unit: 10 Pieces


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Q'ty Per Pack (piece)	Opposite Side (mm)	Total Length (mm)	Weight (g)
371-1951	B33-2.5-25.4H	¥122*	—	10	2.5	25.4	5.5
371-1986	B33-4-33.3H	¥125*	—	10	4.0	33.3	7.5
371-1994	B33-5-33.3H	¥125*	—	10	5.0	33.3	8.5
371-2010	B33-6-33.3H	¥125*	—	10	6.0	33.3	9.5

Contact us:0120-999-914 <http://www.vessel.co.jp/>

VESEL Stock 1,489 Items

## Hex Bit (with magnet)

- Features • A bit for a bolt with a hole used for mechanical equipment and motorcycles.  
 Specs • Shank Diameter: 6.35mm  
 • Blade Edge: With magnet  
 Origin • Japan

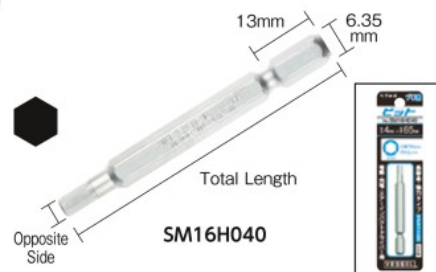

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
371-5035	SM16H020	¥226	—	2.0	65	10	21
371-5043	SM16H025	¥226	—	2.5	65	10	21
371-5051	SM16H030	¥226	—	3.0	65	10	21
371-5060	SM16H040	¥226	—	4.0	65	10	22
371-5078	SM16H050	¥226	—	5.0	65	10	23
371-5086	SM16H060	¥226	—	6.0	65	10	24
371-5094	SM16H080	¥271	—	8.0	65	10	29

Contact us:0120-999-914 <http://www.vessel.co.jp/>