

Attachments for Bits

For Impact, Electric Screwdriver, see p. 5-77 to 119, 124 to 156. For Air Screwdriver, see p. 5-459 to 467

Driver Bits

Double End Drill Bit

Single End Drill Bit

Torsion Bits

Bits for Electric Screwdriver

Bits for Special-Purpose

Attachments for Bits

TRUSCO Stock **38,650** Items

Flexible Shaft



- Features**
- Can be installed on both charging and electric screwdriver.
 - Electric impact screwdriver is also supported.
 - Flexibly bent and is optimum for screw tightening work at corners and edge part.
 - The lock type Bit-holder which bit does not fall is adopted.
- Specs**
- Shank Diameter: 6.35mm
 - Max Working Angle: 60°
- Accessories**
- Double End Drill Bit
 - No. 2 x 45 1 Piece
- Origin**
- Taiwan

Warning

- When using high torque with an impact screwdriver, there is a possibility of damage. Please use without imposing excessive load.

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Input Drive (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
383-1400	TFS-300N	¥2,916	¥3,150	6.35	300	6	290

Contact us:0120-509-849 <http://www.orange-book.com/>

SUNFLAG Stock **290** Items

"Durable Type Flexible Bit"



- Features**
- Optimum for work by the wall, in corners, and in hard to reach places.
 - The one-touch sleeve portion securely catches the bit with a double ball mechanism.
- Specs Origin**
- Shank Diameter: 6.35mm
 - Japan



Suitable for corner section.


SHINKI MANUFACTURING Co.Ltd

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Input Drive (mm)	Total Length (mm)	Accessory Bit	SPQ (piece)	Weight (g)
772-7593	FRS-200	¥2,037	¥2,200	6.35	200	⌀2 x 45mm	6	160
772-7607	FRS-300	¥3,055	¥3,300	6.35	300	⌀2 x 45mm	6	240

Contact us:06-6971-6131 <http://www.sunflag.co.jp/>

TRUSCO Stock **38,650** Items

Long Bit Holder

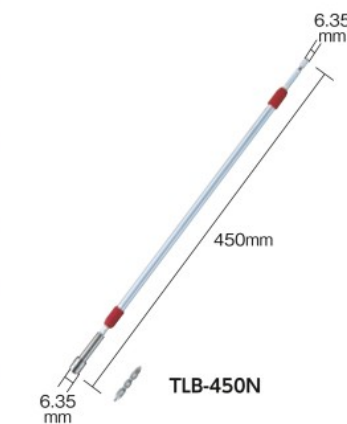

- Features**
- Attached to the electric charge screwdriver, it is optimum for work such as places out of reach.
 - Can change the gripping position according to the work, you can perform stable screwdriver without fluctuation the shaft.
- Specs**
- Shank Diameter: 6.35mm
- Accessories**
- Double End Drill Bit
 - No. 2 x 45 1 Piece
- Origin**
- Japan



Warning

- Because the shaft is pipe-shaped, it does not rotate.

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Input Drive (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
383-1418	TLB-450N	¥2,222	¥2,400	6.35	450	6	172

 
Contact us:0120-509-849 <http://www.orange-book.com/>

VESSEL Stock **1,489** Items

Long Bit Holder



- Features**
- Suitable for tightening screws in places where it is difficult to enter by screws or obstacles near highs and deep points.
- Specs**
- Shank Diameter: 6.35mm
- Origin**
- Japan



Order Code	Item No.	Price (per piece)	MSRP (per piece)	Input Drive (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
323-0104	EXJ150	¥1,511	-	6.35	150	5	100
323-0112	EXJ300	¥1,877	-	6.35	300	5	232


Contact us:0120-999-914 <http://www.vessel.co.jp/>

ANEX Stock **823** Items

Powerful Long Bit Holder



- Features**
- Can use socket bit, hole saw, and gimlet. Suitable for high-torque work.
 - A replaceable shaft type that can be replaced even if the bit twists and snaps as a result of hard work.
- Specs**
- Shank Diameter: 6.35mm
- Accessories**
- Double ended bit
 - No.2 x 45 1 piece,
 - No.2 x 65 1 piece
- Origin**
- Japan

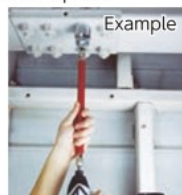

Kaneko Mfg Corporation

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Input Drive (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
469-7626	ALHP-300	¥4,089	¥5,300	6.35	300	3	370

Contact us:0256-32-6321 <http://www.anextool.co.jp/>