

Angles for Pipe Support

The number next to the logo mark indicates items in stock for each brand.

Valves

Screwed Type Pipe Fittings

High Pressure Joints

Welding Fittings

Flanges

Flexible Metal Hoses

Piping Joints for Minor Diameters

Sanitary Pipe Couplings

PVC Pipes

PVC Pipe Joints

PVC Valves

Joints for Water Piping

Protect Accessories for Plumbing

Support Accessories for Plumbing

Maintenance Accessories for Plumbing

Air Conditioning Materials

Valve·Pipe Identifying Goods

Spray Nozzles

TRUSCO **Stock 38,650 Items**

Perforated Angle for Piping Support (both hole type/50 type/5 pieces set)



- Features** • Just by cutting at the site without welding, can install with bolts.
Specs • Long hole: 13 x 40mm
 • Double Hole Type
Origin • Japan



TKL5-W210-S

Stainless Steel

Materials • Stainless Steel (SUS304)

Order Unit: 1 Set

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per set)	MSRP (per set)	W x L (mm)	Thickness (mm)	Q'ty Per Set (piece)	SPQ (set)	Weight (kg/set)
287-2501	TKL5-W210-S	¥64,800	¥70,000	50 x 2100	4.0	5	1	32
287-2510	TKL5-W240-S	¥74,057	¥80,000	50 x 2400	4.0	5	1	36


Steel

Materials • Steel (SPHC) • Surface Treatment: Unichrome Plated Finishing

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	W x L (mm)	Thickness (mm)	Q'ty Per Set (piece)	SPQ (set)	Weight (kg/set)
287-2480	TKL5-W210-U	¥19,070	¥20,600	50 x 2100	4.5	5	1	35
287-2498	TKL5-W240-U	¥21,106	¥22,800	50 x 2400	4.5	5	1	40

Contact us: 0120-509-849 <http://www.orange-book.com/>

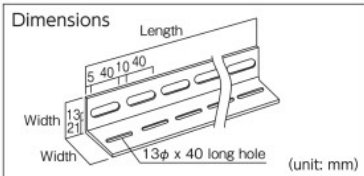

TRUSCO **Stock 38,650 Items**

Multi Angle for Piping Support (single hole type/40 type/5 pieces set)



- Features** • Just by cutting at the site without welding, can install with bolts.
Specs • Long Hole: 10 x 25mm
 • Nail Hole: 4.5mm
 • Single hole type
Origin • Japan



TKLM-S180-S

Stainless Steel

Materials • Stainless Steel (SUS304)

Order Unit: 1 Set

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per set)	MSRP (per set)	W x L (mm)	Thickness (mm)	Q'ty Per Set (piece)	SPQ (set)	Weight (kg/set)
490-0022	TKLM-S180-S	¥36,566	¥39,500	40 x 1800	3.0	5	1	16
490-0031	TKLM-S240-S	¥48,600	¥52,500	40 x 2400	3.0	5	1	22


Steel

Materials • Steel (SPHC) • Surface Treatment: Unichrome Plated Finishing

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	W x L (mm)	Thickness (mm)	Q'ty Per Set (piece)	SPQ (set)	Weight (kg/set)
490-0049	TKLM-S180-U	¥9,257	¥10,000	40 x 1800	3.2	5	1	17
490-0057	TKLM-S240-U	¥12,312	¥13,300	40 x 2400	3.2	5	1	23

Contact us: 0120-509-849 <http://www.orange-book.com/>

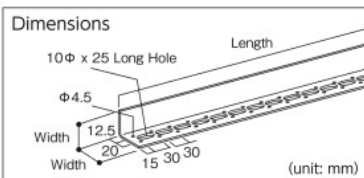

TRUSCO **Stock 38,650 Items**

Perforated Angle for Piping Support (single hole type/40 type/5 pieces set)



- Features** • Just by cutting at the site without welding, can install with bolts.
Specs • Long Hole: 11 x 40mm
 • Single hole type
Origin • Japan



TKL4-S210-S

Stainless Steel

Materials • Stainless Steel (SUS304)

Order Unit: 1 Set

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per set)	MSRP (per set)	W x L (mm)	Thickness (mm)	Q'ty Per Set (piece)	SPQ (set)	Weight (kg/set)
490-0065	TKL4-S210-S	¥39,713	¥42,900	40 x 2100	3.0	5	1	19
490-0073	TKL4-S240-S	¥45,360	¥49,000	40 x 2400	3.0	5	1	22

Steel

Materials • Steel (SPHC) • Surface Treatment: Unichrome Plated Finishing

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	W x L (mm)	Thickness (mm)	Q'ty Per Set (piece)	SPQ (set)	Weight (kg/set)
490-0081	TKL4-S210-U	¥10,923	¥11,800	40 x 2100	3.2	5	1	20
490-0090	TKL4-S240-U	¥12,312	¥13,300	40 x 2400	3.2	5	1	23

Contact us: 0120-509-849 <http://www.orange-book.com/>

