


Firm Neoprene Foam

Neoprene is the most commonly used foam material due to its good balance of strength, oil, water, and weather resistance. Common applications include industrial gaskets to seal water, air, dust, and other environmental items, automotive gaskets, and athletic equipment. This firm Neoprene is stronger and more durable than our standard offering for the most demanding of applications.

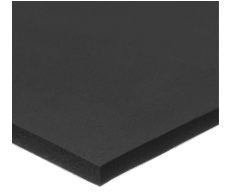

Part Number	Shape	Cell Type	Material	Grade	Thickness	Width	Length	Color	Firmness	Backing Type	Texture	Specs Met
ZUSANSR-F-1	Strip	Closed Cell	Neoprene	Standard	1/16"	1/4"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-4	Strip	Closed Cell	Neoprene	Standard	1/16"	3/8"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-8	Strip	Closed Cell	Neoprene	Standard	1/16"	1/2"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-13	Strip	Closed Cell	Neoprene	Standard	1/16"	3/4"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-18	Strip	Closed Cell	Neoprene	Standard	1/16"	1"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-23	Strip	Closed Cell	Neoprene	Standard	1/16"	2"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-2	Strip	Closed Cell	Neoprene	Standard	1/8"	1/4"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-5	Strip	Closed Cell	Neoprene	Standard	1/8"	3/8"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-9	Strip	Closed Cell	Neoprene	Standard	1/8"	1/2"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-14	Strip	Closed Cell	Neoprene	Standard	1/8"	3/4"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-19	Strip	Closed Cell	Neoprene	Standard	1/8"	1"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-24	Strip	Closed Cell	Neoprene	Standard	1/8"	2"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-3	Strip	Closed Cell	Neoprene	Standard	1/4"	1/4"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-6	Strip	Closed Cell	Neoprene	Standard	1/4"	3/8"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-10	Strip	Closed Cell	Neoprene	Standard	1/4"	1/2"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-15	Strip	Closed Cell	Neoprene	Standard	1/4"	3/4"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-20	Strip	Closed Cell	Neoprene	Standard	1/4"	1"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-25	Strip	Closed Cell	Neoprene	Standard	1/4"	2"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-7	Strip	Closed Cell	Neoprene	Standard	3/8"	3/8"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-11	Strip	Closed Cell	Neoprene	Standard	3/8"	1/2"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-16	Strip	Closed Cell	Neoprene	Standard	3/8"	3/4"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-21	Strip	Closed Cell	Neoprene	Standard	3/8"	1"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-26	Strip	Closed Cell	Neoprene	Standard	3/8"	2"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-12	Strip	Closed Cell	Neoprene	Standard	1/2"	1/2"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-17	Strip	Closed Cell	Neoprene	Standard	1/2"	3/4"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-22	Strip	Closed Cell	Neoprene	Standard	1/2"	1"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-27	Strip	Closed Cell	Neoprene	Standard	1/2"	2"	10 ft.	Black	Firm (14+ psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-201	Sheet	Closed Cell	Neoprene	Standard	1/16"	12"	12"	Black	Firm (14+ psi)	Plain	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-206	Sheet	Closed Cell	Neoprene	Standard	1/16"	12"	24"	Black	Firm (14+ psi)	Plain	Smooth	ASTM D1056 2C5, FMVSS-302
ZUSANSR-F-221	Sheet	Closed Cell	Neoprene	Standard	1/16"	36"	12"	Black	Firm (14+ psi)	Plain	Smooth	ASTM D1056 2C4, FMVSS-302
ZUSANSR-F-226	Sheet	Closed Cell	Neoprene	Standard	1/16"	36"	36"	Black	Firm (14+ psi)	Plain	Smooth	ASTM D1056 2C4, FMVSS-302