


Fire Retardant Neoprene Foam

Neoprene is the most commonly used foam material due to its good balance of strength, oil, water, and weather resistance. Common applications include industrial gaskets to seal water, air, dust, and other environmental items, automotive gaskets, and athletic equipment. This neoprene is lighter and easier to compress than other Neoprene foams. It is also UL listed for flame retardance.

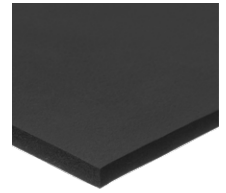

Part Number	Shape	Cell Type	Material	Grade	Thickness	Width	Length	Color	Firmness	Backing Type	Texture	Specs Met
ZUSANSR-FR-1	Strip	Closed Cell	Neoprene	Fire Retardant	1/16"	1/4"	10 ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-4	Strip	Closed Cell	Neoprene	Fire Retardant	1/16"	3/8"	10 ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-8	Strip	Closed Cell	Neoprene	Fire Retardant	1/16"	1/2"	10 ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-13	Strip	Closed Cell	Neoprene	Fire Retardant	1/16"	3/4"	10 ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-18	Strip	Closed Cell	Neoprene	Fire Retardant	1/16"	1"	10 ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-23	Strip	Closed Cell	Neoprene	Fire Retardant	1/16"	2"	10 ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-246	Strip	Closed Cell	Neoprene	Fire Retardant	1/16"	3"	10ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-251	Strip	Closed Cell	Neoprene	Fire Retardant	1/16"	4"	10ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-256	Strip	Closed Cell	Neoprene	Fire Retardant	1/16"	6"	10ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-2	Strip	Closed Cell	Neoprene	Fire Retardant	1/8"	1/4"	10 ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-5	Strip	Closed Cell	Neoprene	Fire Retardant	1/8"	3/8"	10 ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-9	Strip	Closed Cell	Neoprene	Fire Retardant	1/8"	1/2"	10 ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-14	Strip	Closed Cell	Neoprene	Fire Retardant	1/8"	3/4"	10 ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-19	Strip	Closed Cell	Neoprene	Fire Retardant	1/8"	1"	10 ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-24	Strip	Closed Cell	Neoprene	Fire Retardant	1/8"	2"	10 ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-247	Strip	Closed Cell	Neoprene	Fire Retardant	1/8"	3"	10ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-252	Strip	Closed Cell	Neoprene	Fire Retardant	1/8"	4"	10ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-257	Strip	Closed Cell	Neoprene	Fire Retardant	1/8"	6"	10ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-3	Strip	Closed Cell	Neoprene	Fire Retardant	1/4"	1/4"	10 ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-6	Strip	Closed Cell	Neoprene	Fire Retardant	1/4"	3/8"	10 ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-10	Strip	Closed Cell	Neoprene	Fire Retardant	1/4"	1/2"	10 ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-15	Strip	Closed Cell	Neoprene	Fire Retardant	1/4"	3/4"	10 ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-20	Strip	Closed Cell	Neoprene	Fire Retardant	1/4"	1"	10 ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-25	Strip	Closed Cell	Neoprene	Fire Retardant	1/4"	2"	10 ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-248	Strip	Closed Cell	Neoprene	Fire Retardant	1/4"	3"	10ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-253	Strip	Closed Cell	Neoprene	Fire Retardant	1/4"	4"	10ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-258	Strip	Closed Cell	Neoprene	Fire Retardant	1/4"	6"	10ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-7	Strip	Closed Cell	Neoprene	Fire Retardant	3/8"	3/8"	10 ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-11	Strip	Closed Cell	Neoprene	Fire Retardant	3/8"	1/2"	10 ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-16	Strip	Closed Cell	Neoprene	Fire Retardant	3/8"	3/4"	10 ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1
ZUSANSR-FR-21	Strip	Closed Cell	Neoprene	Fire Retardant	3/8"	1"	10 ft.	Black	Extra Soft (0 - 4 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2C1, UL 94 HF-1