


# Abrasion Resistant SBR

## SBR Rubber

SBR is a good economical choice for general purpose use and offers good abrasion resistance.

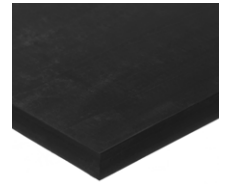

Part Number	Shape	Material	Grade	Durometer	Thickness	Width	Length	Color	Backing Type	Texture	Specs Met
BULK-RS-SBR75-130	Strip	SBR	Standard	75A	1/16"	2"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-139	Strip	SBR	Standard	75A	1/16"	4"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-148	Strip	SBR	Standard	75A	1/16"	6"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-131	Strip	SBR	Standard	75A	3/32"	2"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-140	Strip	SBR	Standard	75A	3/32"	4"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-149	Strip	SBR	Standard	75A	3/32"	6"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-132	Strip	SBR	Standard	75A	1/8"	2"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-141	Strip	SBR	Standard	75A	1/8"	4"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-150	Strip	SBR	Standard	75A	1/8"	6"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-133	Strip	SBR	Standard	75A	3/16"	2"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-142	Strip	SBR	Standard	75A	3/16"	4"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-151	Strip	SBR	Standard	75A	3/16"	6"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-134	Strip	SBR	Standard	75A	1/4"	2"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-143	Strip	SBR	Standard	75A	1/4"	4"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-152	Strip	SBR	Standard	75A	1/4"	6"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-135	Strip	SBR	Standard	75A	3/8"	2"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-144	Strip	SBR	Standard	75A	3/8"	4"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-153	Strip	SBR	Standard	75A	3/8"	6"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-136	Strip	SBR	Standard	75A	1/2"	2"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-145	Strip	SBR	Standard	75A	1/2"	4"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-154	Strip	SBR	Standard	75A	1/2"	6"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-137	Strip	SBR	Standard	75A	3/4"	2"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-146	Strip	SBR	Standard	75A	3/4"	4"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-155	Strip	SBR	Standard	75A	3/4"	6"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-138	Strip	SBR	Standard	75A	1"	2"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-147	Strip	SBR	Standard	75A	1"	4"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-156	Strip	SBR	Standard	75A	1"	6"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR60-7	Sheet	SBR	Standard	60A	1/16"	12"	12"	Black	Plain	Smooth	ASTM D2000 AA 603
BULK-RS-SBR60-3	Sheet	SBR	Standard	60A	1/16"	36"	12"	Black	Plain	Smooth	ASTM D2000 AA 603
BULK-RS-SBR60-83	Sheet	SBR	Standard	60A	1/16"	36"	24"	Black	Plain	Smooth	ASTM D2000 AA 603
BULK-RS-SBR60-5	Sheet	SBR	Standard	60A	1/16"	36"	36"	Black	Plain	Smooth	ASTM D2000 AA 603
BULK-RS-SBR60-8	Sheet	SBR	Standard	60A	1/8"	12"	12"	Black	Plain	Smooth	ASTM D2000 AA 603
BULK-RS-SBR60-4	Sheet	SBR	Standard	60A	1/8"	36"	12"	Black	Plain	Smooth	ASTM D2000 AA 603
BULK-RS-SBR60-84	Sheet	SBR	Standard	60A	1/8"	36"	24"	Black	Plain	Smooth	ASTM D2000 AA 603
BULK-RS-SBR60-6	Sheet	SBR	Standard	60A	1/8"	36"	36"	Black	Plain	Smooth	ASTM D2000 AA 603
BULK-RS-SBR60-13	Sheet	SBR	Standard	60A	1/16"	36"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 AA 603
BULK-RS-SBR60-14	Sheet	SBR	Standard	60A	1/8"	36"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 AA 603
BULK-RS-SBR75-157	Sheet	SBR	Standard	75A	1/16"	12"	12"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-166	Sheet	SBR	Standard	75A	1/16"	12"	24"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-19	Sheet	SBR	Standard	75A	1/16"	36"	12"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-28	Sheet	SBR	Standard	75A	1/16"	36"	24"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-37	Sheet	SBR	Standard	75A	1/16"	36"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-158	Sheet	SBR	Standard	75A	3/32"	12"	12"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-167	Sheet	SBR	Standard	75A	3/32"	12"	24"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-20	Sheet	SBR	Standard	75A	3/32"	36"	12"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-29	Sheet	SBR	Standard	75A	3/32"	36"	24"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-38	Sheet	SBR	Standard	75A	3/32"	36"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-159	Sheet	SBR	Standard	75A	1/8"	12"	12"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-168	Sheet	SBR	Standard	75A	1/8"	12"	24"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-21	Sheet	SBR	Standard	75A	1/8"	36"	12"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-30	Sheet	SBR	Standard	75A	1/8"	36"	24"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-39	Sheet	SBR	Standard	75A	1/8"	36"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-160	Sheet	SBR	Standard	75A	3/16"	12"	12"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-169	Sheet	SBR	Standard	75A	3/16"	12"	24"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBR75-22	Sheet	SBR	Standard	75A	3/16"	36"	12"	Black	Plain	Smooth	ASTM D2000 AA 706