


High Strength SBR Rubber

Stronger and more durable than standard SBR for more demanding applications. SBR is a good economical choice for general purpose use and offers good abrasion resistance.

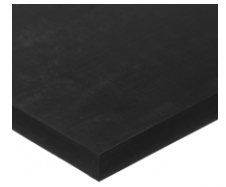

Part Number	Shape	Material	Grade	Durometer	Thickness	Width	Length	Color	Backing Type	Texture	Specs Met
BULK-RS-SBRHS60-91	Strip	SBR	High Strength	60A	3/4"	6"	10 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-93	Strip	SBR	High Strength	60A	3/4"	6"	25 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-92	Strip	SBR	High Strength	60A	1"	6"	10 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-94	Strip	SBR	High Strength	60A	1"	6"	25 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-13	Sheet	SBR	High Strength	60A	1/4"	6"	12"	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-19	Sheet	SBR	High Strength	60A	1/4"	6"	24"	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-25	Sheet	SBR	High Strength	60A	1/4"	6"	36"	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-16	Sheet	SBR	High Strength	60A	1/4"	12"	12"	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-22	Sheet	SBR	High Strength	60A	1/4"	12"	24"	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-28	Sheet	SBR	High Strength	60A	1/4"	12"	36"	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-14	Sheet	SBR	High Strength	60A	3/8"	6"	12"	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-20	Sheet	SBR	High Strength	60A	3/8"	6"	24"	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-26	Sheet	SBR	High Strength	60A	3/8"	6"	36"	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-17	Sheet	SBR	High Strength	60A	3/8"	12"	12"	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-23	Sheet	SBR	High Strength	60A	3/8"	12"	24"	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-29	Sheet	SBR	High Strength	60A	3/8"	12"	36"	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-15	Sheet	SBR	High Strength	60A	1/2"	6"	12"	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-21	Sheet	SBR	High Strength	60A	1/2"	6"	24"	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-27	Sheet	SBR	High Strength	60A	1/2"	6"	36"	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-18	Sheet	SBR	High Strength	60A	1/2"	12"	12"	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-24	Sheet	SBR	High Strength	60A	1/2"	12"	24"	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-30	Sheet	SBR	High Strength	60A	1/2"	12"	36"	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-31	Roll	SBR	High Strength	60A	1/4"	6"	4 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-37	Roll	SBR	High Strength	60A	1/4"	6"	5 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-43	Roll	SBR	High Strength	60A	1/4"	6"	6 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-49	Roll	SBR	High Strength	60A	1/4"	6"	7 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-55	Roll	SBR	High Strength	60A	1/4"	6"	8 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-61	Roll	SBR	High Strength	60A	1/4"	6"	9 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-67	Roll	SBR	High Strength	60A	1/4"	6"	10 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-79	Roll	SBR	High Strength	60A	1/4"	6"	25 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-82	Roll	SBR	High Strength	60A	1/4"	6"	50 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-4	Roll	SBR	High Strength	60A	1/4"	6"	60 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-34	Roll	SBR	High Strength	60A	1/4"	12"	4 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-40	Roll	SBR	High Strength	60A	1/4"	12"	5 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-46	Roll	SBR	High Strength	60A	1/4"	12"	6 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-52	Roll	SBR	High Strength	60A	1/4"	12"	7 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-58	Roll	SBR	High Strength	60A	1/4"	12"	8 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-64	Roll	SBR	High Strength	60A	1/4"	12"	9 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-70	Roll	SBR	High Strength	60A	1/4"	12"	10 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-85	Roll	SBR	High Strength	60A	1/4"	12"	25 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-88	Roll	SBR	High Strength	60A	1/4"	12"	50 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-1	Roll	SBR	High Strength	60A	1/4"	12"	60 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-32	Roll	SBR	High Strength	60A	3/8"	6"	4 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-38	Roll	SBR	High Strength	60A	3/8"	6"	5 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-44	Roll	SBR	High Strength	60A	3/8"	6"	6 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-50	Roll	SBR	High Strength	60A	3/8"	6"	7 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-56	Roll	SBR	High Strength	60A	3/8"	6"	8 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-62	Roll	SBR	High Strength	60A	3/8"	6"	9 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-68	Roll	SBR	High Strength	60A	3/8"	6"	10 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-80	Roll	SBR	High Strength	60A	3/8"	6"	25 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-83	Roll	SBR	High Strength	60A	3/8"	6"	50 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-5	Roll	SBR	High Strength	60A	3/8"	6"	60 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-35	Roll	SBR	High Strength	60A	3/8"	12"	4 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-41	Roll	SBR	High Strength	60A	3/8"	12"	5 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-47	Roll	SBR	High Strength	60A	3/8"	12"	6 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-53	Roll	SBR	High Strength	60A	3/8"	12"	7 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-59	Roll	SBR	High Strength	60A	3/8"	12"	8 ft.	Black	Plain	Smooth	ASTM D2000 AA 607
BULK-RS-SBRHS60-65	Roll	SBR	High Strength	60A	3/8"	12"	9 ft.	Black	Plain	Smooth	ASTM D2000 AA 607