


Polycarbonate

Polycarbonate is clear for applications that require seeing through the plastic and has excellent resistance to impact, shock, and strikes.

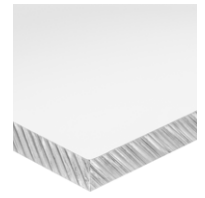

Part Number	Shape	Material	Grade	Thickness	Width	Length	Color	Clarity	Backing Type
BULK-PF-PC-7	Film	Polycarbonate	Standard	0.005"	40"	1 ft.	Clear	Clear	Plain
BULK-PF-PC-8	Film	Polycarbonate	Standard	0.005"	40"	3 ft.	Clear	Clear	Plain
BULK-PF-PC-9	Film	Polycarbonate	Standard	0.005"	40"	5 ft.	Clear	Clear	Plain
BULK-PF-PC-10	Film	Polycarbonate	Standard	0.005"	40"	10 ft.	Clear	Clear	Plain
BULK-PF-PC-11	Film	Polycarbonate	Standard	0.005"	40"	25 ft.	Clear	Clear	Plain
BULK-PF-PC-12	Film	Polycarbonate	Standard	0.005"	40"	50 ft.	Clear	Clear	Plain
BULK-PF-PC-13	Film	Polycarbonate	Standard	0.005"	40"	100 ft.	Clear	Clear	Plain
BULK-PF-PC-1	Film	Polycarbonate	Standard	0.005"	40"	1,820 ft.	Clear	Clear	Plain
BULK-PF-PC-14	Film	Polycarbonate	Standard	0.01"	40"	1 ft.	Clear	Clear	Plain
BULK-PF-PC-15	Film	Polycarbonate	Standard	0.01"	40"	3 ft.	Clear	Clear	Plain
BULK-PF-PC-16	Film	Polycarbonate	Standard	0.01"	40"	5 ft.	Clear	Clear	Plain
BULK-PF-PC-17	Film	Polycarbonate	Standard	0.01"	40"	10 ft.	Clear	Clear	Plain
BULK-PF-PC-18	Film	Polycarbonate	Standard	0.01"	40"	25 ft.	Clear	Clear	Plain
BULK-PF-PC-19	Film	Polycarbonate	Standard	0.01"	40"	50 ft.	Clear	Clear	Plain
BULK-PF-PC-20	Film	Polycarbonate	Standard	0.01"	40"	100 ft.	Clear	Clear	Plain
BULK-PF-PC-2	Film	Polycarbonate	Standard	0.01"	40"	890 ft.	Clear	Clear	Plain
BULK-PF-PC-21	Film	Polycarbonate	Standard	0.015"	40"	1 ft.	Clear	Clear	Plain
BULK-PF-PC-22	Film	Polycarbonate	Standard	0.015"	40"	3 ft.	Clear	Clear	Plain
BULK-PF-PC-23	Film	Polycarbonate	Standard	0.015"	40"	5 ft.	Clear	Clear	Plain
BULK-PF-PC-24	Film	Polycarbonate	Standard	0.015"	40"	10 ft.	Clear	Clear	Plain
BULK-PF-PC-25	Film	Polycarbonate	Standard	0.015"	40"	25 ft.	Clear	Clear	Plain
BULK-PF-PC-26	Film	Polycarbonate	Standard	0.015"	40"	50 ft.	Clear	Clear	Plain
BULK-PF-PC-27	Film	Polycarbonate	Standard	0.015"	40"	100 ft.	Clear	Clear	Plain
BULK-PF-PC-3	Film	Polycarbonate	Standard	0.015"	40"	600 ft.	Clear	Clear	Plain
BULK-PF-PC-28	Film	Polycarbonate	Standard	0.02"	12"	12"	Clear	Clear	Plain
BULK-PF-PC-29	Film	Polycarbonate	Standard	0.02"	12"	24"	Clear	Clear	Plain
BULK-PF-PC-30	Film	Polycarbonate	Standard	0.02"	24"	24"	Clear	Clear	Plain
BULK-PF-PC-31	Film	Polycarbonate	Standard	0.02"	24"	48"	Clear	Clear	Plain
BULK-PF-PC-32	Film	Polycarbonate	Standard	0.02"	48"	48"	Clear	Clear	Plain
BULK-PF-PC-4	Film	Polycarbonate	Standard	0.02"	48"	96"	Clear	Clear	Plain
BULK-PF-PC-34	Film	Polycarbonate	Standard	0.03"	12"	12"	Clear	Clear	Plain
BULK-PF-PC-35	Film	Polycarbonate	Standard	0.03"	12"	24"	Clear	Clear	Plain
BULK-PF-PC-36	Film	Polycarbonate	Standard	0.03"	24"	24"	Clear	Clear	Plain
BULK-PF-PC-37	Film	Polycarbonate	Standard	0.03"	24"	48"	Clear	Clear	Plain
BULK-PF-PC-38	Film	Polycarbonate	Standard	0.03"	48"	48"	Clear	Clear	Plain
BULK-PF-PC-5	Film	Polycarbonate	Standard	0.03"	48"	96"	Clear	Clear	Plain
BULK-PF-PC-40	Film	Polycarbonate	Standard	0.04"	12"	12"	Clear	Clear	Plain
BULK-PF-PC-41	Film	Polycarbonate	Standard	0.04"	12"	24"	Clear	Clear	Plain
BULK-PF-PC-42	Film	Polycarbonate	Standard	0.04"	24"	24"	Clear	Clear	Plain
BULK-PF-PC-43	Film	Polycarbonate	Standard	0.04"	24"	48"	Clear	Clear	Plain
BULK-PF-PC-44	Film	Polycarbonate	Standard	0.04"	48"	48"	Clear	Clear	Plain
BULK-PF-PC-6	Film	Polycarbonate	Standard	0.04"	48"	96"	Clear	Clear	Plain