


# +SP(N+SP)

## Plus Series Spiral Fluted Taps



Segment : 1C

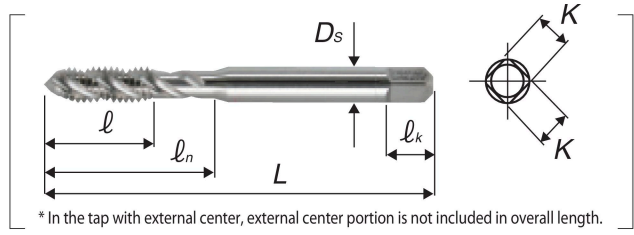

N+SP is available as long as it lasts. +SP takes the place of N+SP.

○\* Oversize

Size	Stock	Code	Chamfer	Class	L (mm)	l (mm)	ln (mm)	Ds (mm)	K (mm)	lk (mm)	Flute	Type
<b>For Metric Threads</b>												
M1.2×0.25	○*	SNPP1.2B	2.5P	P1	36	4.5	-	3	2.5	5	2	a
M1.4×0.3	◎*	SNPP1.4C	2.5P	P1	36	5.4	-	3	2.5	5	2	a
M1.6×0.35	◎*	SNPP1.6D	2.5P	P1	36	6.3	-	3	2.5	5	2	b
M1.7×0.35	◎*	SNPP1.7D	2.5P	P1	36	6.3	-	3	2.5	5	2	b
	○*	SNPQ1.7D		P2								
	△*	SNPR1.7D		P3								
M1.8×0.35	△*	SNPP1.8D	2.5P	P1	42	6.3	-	3	2.5	5	2	b
M2×0.4	◎	SNPP2.0E	2.5P	P1	42	7.2	12	3	2.5	5	2	c
	○	SNPQ2.0E		P2								
	◎	SNPR2.0E		P3								
	△	SNPS2.0E		P4								
M2.2×0.45	○	SNPP2.2F	2.5P	P1	42	8.1	12	3	2.5	5	2	c
M2.3×0.4	○	SNPP2.3E	2.5P	P1	42	7.2	12	3	2.5	5	2	c
	△	SNPQ2.3E		P2								
	△	SNPR2.3E		P3								
	△	SNPS2.3E		P4								
M2.5×0.45	◎	SNPP2.5F	2.5P	P1	46	8.1	14	3	2.5	5	2	c
	○	SNPQ2.5F		P2								
	○	SNPR2.5F		P3								
	○	SNPS2.5F		P4								
M2.6×0.45	◎	SNPP2.6F	2.5P	P1	46	8.1	14	3	2.5	5	2	c
	○	SNPQ2.6F		P2								
	○	SNPR2.6F		P3								
	△	SNPS2.6F		P4								
M3×0.5	◎	SNPP3.0G	2.5P	P1	46	9	14	4	3.2	6	3	c
	○	SNPQ3.0G		P2								
	○	SNPR3.0G		P3								
	○	SNPS3.0G		P4								
3M0.6	△*	SNPP3.0H	2.5P	P1	46	9	14	4	3.2	6	3	c
M3.5×0.6	○	SNPP3.5H	2.5P	P1	52	11	16	5	4	7	3	c
	△	SNPQ3.5H		P2								
	△	SNPR3.5H		P3								
	△	SNPS3.5H		P4								
M4×0.7	◎	SNPQ4.0I	2.5P	P2	52	11	17	5	4	7	3	c

The products having \*mark in the stock column will be available as long as they last.