

PMS Type ϕ 100 130 150 200


Swivel

Plate Type

BZP (Brilliant Zinc Plating)	CP (Chromium Plating)
Single Bearing	Double Bearing
Single Stopper	Double Stopper



PMS-150AW

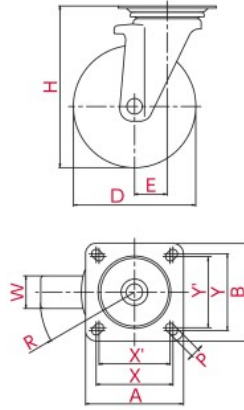

Mounting Method **Plate Type**



Usage

- Flat Trolley
- Hand Trolley
- Server Rack
- Roll Box Pallet
- Towing Trolley*
- Office Chair
- Machinery and equipment
- Copying Machine
- Furniture
- Display Rack
- Refrigeration and cold storage showcase
- Others

Use together with **Fixed**

The picture is a typical product image.

Order Example: **PMS** - **150** **AW**
Bracket Type Wheel Diameter Wheel Type

Use together with **Fixed**

PMR Type P.103
 PMR-LB[R] Type P.104
 PMR-LB[L] Type P.105

Wheel Diameter (D[mm])	Product No.	Wheel Material	Load Capacity [daN(kgf)]	Wheel Width (W[mm])	Mounting Height (H[mm])	Mounting Base (A×B[mm])	Mounting Dimensions (X×Y (X'×Y') [mm])	Hole Diameter (P[mm])	Eccentricity (E[mm])	Turning Radius (R[mm])	
100	PMS-100WB	Rubber(Including B)	120(122.4)	32	144	95×95	74×74(67×67)	11	32	82	
	PMS-100UWB/INJ	PU(Including B)	180(183.6)								
	PMS-100GUB		100(102.0)								
	PMS-100APU		180(183.6)								
130	PMS-130WB	Rubber(Including B)	180(183.6)	40	177	110×110	90×90(80×80)	11	40	105	
	PMS-130WB-G	Grey Rubber(Including B)	250(255.0)	35							
	PMS-130UWB/INJ	PU(Including B)		180(183.6)							40
	PMS-130GUB			250(255.0)							35
	PMS-130APU										
150	PMS-150WB	Rubber(Including B)	200(204.0)	40	198	120×120	94×94(87×87)	11	40	115	
	PMS-150AW*		250(255.0)	42							
	PMS-150WB-G	Grey Rubber(Including B)	200(204.0)	40							
	PMS-150UWB/INJ	PU(Including B)	300(306.0)	38							
	PMS-150GUB		200(204.0)	40							
	PMS-150APU		300(306.0)	38							
	PMS-150AUU		350(357.0)	42							
200	PMS-200WB	Rubber(Including B)	250(255.0)	43	250	144×144	120×120(105×105)	11.5	56	156	
	PMS-200AW*		300(306.0)	45							
	PMS-200WB-G	Grey Rubber(Including B)	250(255.0)	43							
	PMS-200UWB/INJ	PU(Including B)	400(408.0)	42							
	PMS-200GUB		250(255.0)	43							
	PMS-200APU		400(408.0)	45							
PMS-200AUU											

*Only AW wheel is adaptable for towing.

• Sign With foot guard type is available. > P.109

Wheel Type

WB Wheel: Steel Tread: Rubber (Including B)	AW Wheel: Aluminum Tread: Rubber (Including B)	WB -G Wheel: Steel Tread: Grey Rubber (Including B)	UWB/INJ Wheel: Steel Tread: PU (Including B)	GUB Wheel: Nylon Tread: PU (Including B)	APU Wheel: Aluminum Tread: PU (Including B)	AUU Wheel: Aluminum Tread: PU (Including B)