

NPG-S Type ϕ 100 125


Swivel

Plate Type

| | |
|------------------------------|----------------|
| BZP (Brilliant Zinc Plating) | Stainless |
| Single Bearing | Double Bearing |
| Single Stopper | Double Stopper |



NPG-100SUES-1

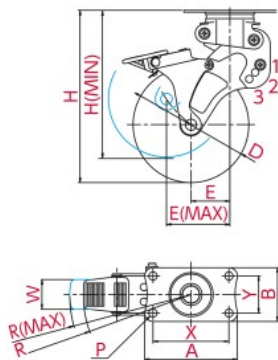

Mounting Method Plate Type



Usage

- Flat Trolley
- Hand Trolley
- Server Rack
- Roll Box Pallet
- Towing Trolley
- Office Chair
- Machinery and equipment
- Copying Machine
- Furniture
- Display Rack
- Refrigeration and cold storage showcase
- Others

Use together with Fixed

The picture is a typical product image.

Order Example: **NPG** - **100** **SUE** **S** - **1**
Bracket Type Wheel Diameter Wheel Type Stopper Proper Load



| Wheel Diameter (D(mm)) | Product No. | Wheel Material | Proper Load [daN(kgf)] | Wheel Width (W(mm)) | Mounting Height (H(mm)) | Mounting Base (AxB(mm)) | Mounting Dimensions (XxY (X'xY') (mm)) | Hole Diameter (P(mm)) | Eccentricity (E(mm)) | Turning Radius (R(mm)) |
|------------------------|---------------|----------------------------|------------------------|---------------------|-------------------------|-------------------------|--|-----------------------|----------------------|------------------------|
| 100 | NPG-100SUES-1 | Antistatic PU(Including B) | 10(10.2) | 28 | 165(~140) | 100x58 | 82x40 | 8.8 | 35(~59) | 111(~115) |
| | NPG-100SUES-2 | | 20(20.4) | | 165(~147) | | | | | |
| | NPG-100SUES-3 | | 30(30.6) | | 165(~150) | | | | | |
| 125 | NPG-125SUES-1 | Antistatic PU(Including B) | 10(10.2) | 32 | 186(~159) | 100x58 | 82x40 | 8.8 | 42(~68) | 117(~131) |
| | NPG-125SUES-2 | | 20(20.4) | | 186(~166) | | | | | |
| | NPG-125SUES-3 | | 30(30.6) | | 186(~170) | | | | | |

*It is the date value in parenthesis when load in maximum.

Wheel Type

SUE
 Wheel: Nylon
 Tread: Antistatic PU (Including B)

Light Duty
 Medium Duty
 Heavy Duty
 Low-Profile Heavy Duty
 Leveling
 Stainless Steel
 Towing
 Shock Absorbing
 Silence
 Office Equipment