



# LR TYPE

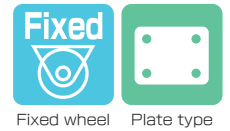

LR-50R

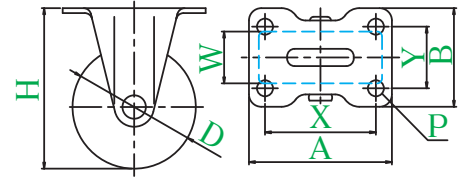

● Description of product number  
**LR - 50 R**  
 Bracket type Wheel diameter Wheel type

Bracket = Trivalent unichrome coating

Product number	Wheels								
		Wheel diameter D(mm)	Wheel width W(mm)	Mounting height H(mm)	Mounting base A × B(mm)	Mounting dimensions X × Y(mm)	Hole diameter P(mm)	Allowance load daN(kgf)	Wheel weight (g)
LR-50	R Rubber wheel	50	20	65	58 × 40	45 × 25	6.5	30(30.6)	125
	N Nylon wheel		21					40(40.8)	100

- Conductive rubber wheel can be manufactured.
- For nylon wheels, black wheels can be manufactured.

## Wheel in use

Refer to P157 for detailed specifications.



R Rubber wheel



N Nylon wheel

- J
- PM
- J2
- RJ2
- SJ
- S
- E
- G
- L
- SA
- H
- CAL -H
- M
- PL
- Silence
- SUS -J2
- SUS -SJ
- SUS -S
- SUS -E
- SUS -H
- P
- SKY
- Equipped with adjuster foot
- Special
- Easy lock
- Wheels